


Hex Thin Nuts – Metric

Also known as jam nuts, they are about half the height of standard hex nuts. Use them in low-clearance applications or jam one against another nut to hold it in place. Nuts have a Class 6H thread fit and meet DIN 439B.

Materials and finishes offered in:

- Aluminum
- 316 H5 Stainless Steel
- 17-4 PH Stainless Steel
- A286 Stainless Steel
- 410 Stainless Steel
- Monel
- Titanium Grade 2
- Titanium Grade 5

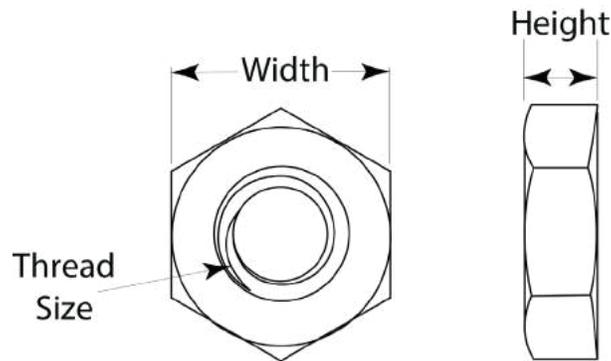

Aluminum Hex Thin Nuts

Thread Size	Width	Height	Aluminum Part Number
M6 x 1	10.00	3.20	ZNJ061M6
M8 x 1.25	13.00	4.00	ZNJ061M8
M10 x 1.5	17.00	5.00	ZNJ061M10
M12 x 1.75	19.00	6.00	ZNJ061M12
M16 x 2	24.00	8.00	ZNJ061M16
M20 x 2.5	30.00	10.00	ZNJ061M20
M24 x 3	36.00	12.00	ZNJ061M24

316 H5 SS Hex Thin Nuts

Thread Size	Width	Height	316 H5 Part Number
M6 x 1	10.00	3.20	ZNJ616M6
M8 x 1.25	13.00	4.00	ZNJ616M8
M10 x 1.5	17.00	5.00	ZNJ616M10
M12 x 1.75	19.00	6.00	ZNJ616M12
M16 x 2	24.00	8.00	ZNJ616M16
M20 x 2.5	30.00	10.00	ZNJ616M20
M24 x 3	36.00	12.00	ZNJ616M24