


DM SERIES FEATURES

DC power now comes in a smaller package. Our slimline single phase models measure as small as 32 mm wide to conserve valuable space on the DIN Rail and in the overall control cabinet!

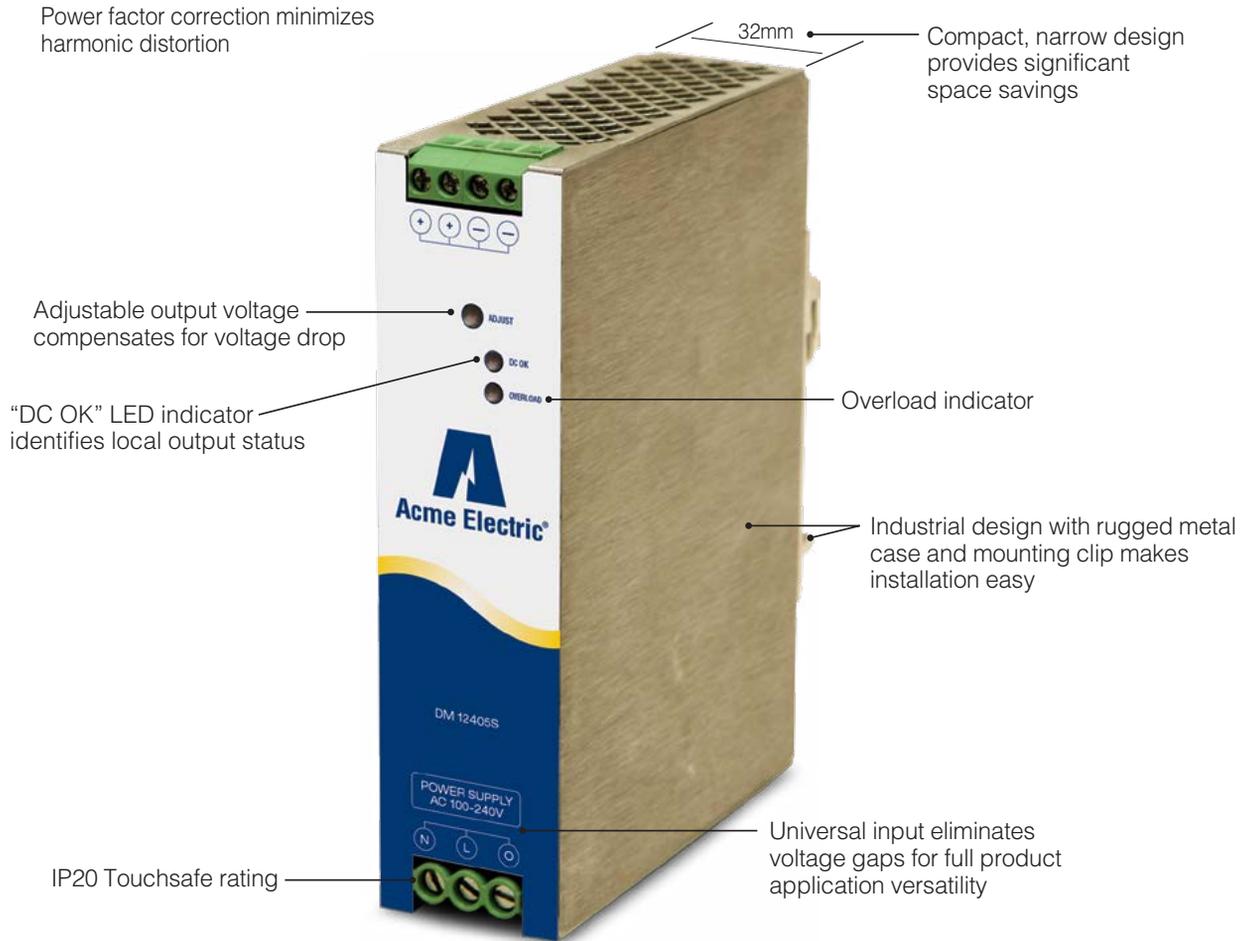

SINGLE PHASE

Catalog Number	Output Power (Watts Max)	Amp Rating	Voltage Range AC	Voltage Range DC	Output Voltage	Efficiency (%)	Operating Temperature	Height (Inches)(Cm.)	Width (Inches)(Cm.)	Depth (Inches)(Cm.)	Weight (Lbs.)(Kg.)
DM112045	54 W	3.4–4.5	90–254 VAC	—	12 VDC (10–16 adj)	86%	-10°C to +60°C	4.88 (124)	1.97 (50)	4.13 (105)	1.08 (0.49)
DM124025	60 W	2.1–2.1	90–254 VAC	—	24 VDC (22–28 adj)	87%	-10°C to +60°C	4.88 (124)	1.97 (50)	4.13 (105)	1.08 (0.49)
DM12420	480 W	17.1–20.0	90–254 VAC	—	24 VDC (22–28 adj)	90%	-10°C to +60°C	5.12 (130)	6.14 (156)	4.96 (126)	4.96 (2.25)
DM13613	480 W	12.0–13.3	90–254 VAC	—	36 VDC (34–40 adj)	90%	-10°C to +60°C	5.12 (130)	6.14 (156)	4.96 (126)	4.96 (2.25)
DM1480125	60 W	1.15–1.25	90–254 VAC	—	48 VDC (46–52 adj)	89%	-10°C to +60°C	4.88 (124)	1.97 (50)	4.13 (105)	1.08 (0.49)
DM14810	480 W	9.2–10.0	90–254 VAC	—	48 VDC (46–52 adj)	90%	-10°C to +60°C	5.12 (130)	6.14 (156)	4.96 (126)	4.96 (2.25)

Frequency: 47-63 Hz for all models

1. Depends upon specific model selection, output voltage and/or upon 120 or 240 VAC operation.