



STAINLESS STEEL

SPECLINE 14 Ga. Fabricated Sinks NSF

Triple Compartments



Item #: _____ Qty #: _____

Model #: _____

Project #: _____

FEATURES:

- Full Skirt Design
- Backsplash has tile edge for ease of installation.
- Sink bowls are 3/4" coved corner and meet NSF requirements.
- Rolled Rim Edge for additional strength.
- Sink Bowls are 14" deep for greater capacity.
- Stainless Steel Legs and Cross Bracing.

CONSTRUCTION:

- All TIG welded.
- Welded areas blended to match adjacent surfaces and to a satin finish.

MATERIAL:

- 1 5/8" diameter stainless steel legs with 1" adjustable stainless steel bullet feet.
- Entire unit is 14 gauge 304 stainless steel.
- Stainless Steel Gussets.

MECHANICAL:

- Supply is 1/2" IPS hot & cold.
- Faucet holes on 8" centers.
- Faucets are not included (**see accessories**).
- Waste drains are 1 1/2" IPS S/S basket type, located in center of sink bowl, and are included.

MODEL #	BOWL SIZE	O.A. Length	# of Drbds.
FS-3-1620	16" x 20"	53"	0
FS-3-1620-18R or L	16" x 20"	68.5"	1
FS-3-1620-18RL	16" x 20"	84"	2
FS-3-1620-24RL	16" x 20"	96"	2
FS-3-1620-36RL	16" x 20"	120"	2
FS-3-1524	15" x 24"	50"	0
FS-3-1524-24R or L	15" x 24"	71.5"	1
FS-3-1524-24RL	15" x 24"	93"	2
FS-3-1818	18" x 18"	59"	0
FS-3-1818-18R or L	18" x 18"	74.5"	1
FS-3-1818-18RL	18" x 18"	90"	2
FS-3-1824	18" x 24"	59"	0
FS-3-1824-18R or L	18" x 24"	74.5"	1
FS-3-1824-24R or L	18" x 24"	80.5"	1
FS-3-1824-18RL	18" x 24"	90"	2
FS-3-1824-24RL	18" x 24"	102"	2
FS-3-2024	20" x 24"	65"	0
FS-3-2024-24R or L	20" x 24"	86.5"	1
FS-3-2024-24RL	20" x 24"	108"	2
† FS-3-2424	24" x 24"	77"	0
† FS-3-2424-18R or L	24" x 24"	92.5"	1
† FS-3-2424-24R or L	24" x 24"	98.5"	1
† FS-3-2424-18RL	24" x 24"	108"	2
† FS-3-2424-24RL	24" x 24"	120"	2

† Requires Two Faucets

ACCESSORIES	Model #	Qty
DRAINS		
FAUCETS		



Customer Service Available To Assist You 1-800-645-3166 8:30 am - 8:00 pm E.S.T.

For Orders & Customer Service:

Email: customer@advancetabco.com or Fax: 631-242-6900


For Smart Fabrication™ Quotes:

Email: smartfab@advancetabco.com or Fax: 631-586-2933


DIMENSIONS and SPECIFICATIONS

TOL Overall: $\pm .500''$
Interior: $\pm .250''$


ALL DIMENSIONS ARE TYPICAL

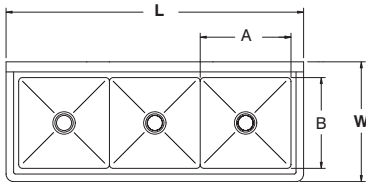

3 COMP - NO DRBDS

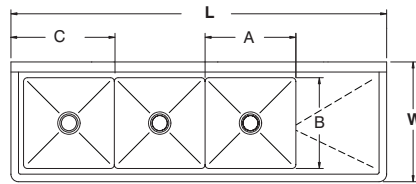

3 COMP - 1 DRBD

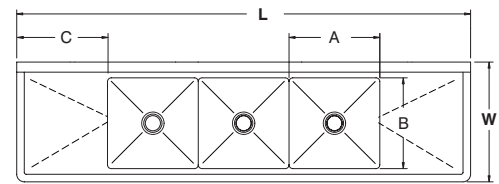

3 COMP - 2 DRBDs

NSF

MODEL #	Length L	Width W	Bowl Size A & B	Drbd. Length C	# of Drbds.	Drbd. Location	Wt	Cu.
FS-3-1620	53"	26"	16" x 20"	0	0	None	140 lbs	27
FS-3-1620-18R or L	68.5"	26"	16" x 20"	18"	1	Specify	160 lbs	35
FS-3-1620-18RL	84"	26"	16" x 20"	18"	2	Both	155 lbs	36
FS-3-1620-24RL	96"	26"	16" x 20"	24"	2	Both	235 lbs	47
FS-3-1824-36RL	120"	26"	16" x 20"	36"	2	Both	280 lbs	59
FS-3-1524	50"	30"	15" x 24"	0	0	None	116 lbs	31
FS-3-1524-24R or L	71.5"	30"	15" x 24"	24"	1	specify	139 lbs	44
FS-3-1524-24RL	93"	30"	15" x 24"	24"	2	Both	163 lbs	56
FS-3-1818	59"	24"	18" x 18"	0	0	None	130 lbs	25
FS-3-1818-18R or L	74.5"	24"	18" x 18"	18"	1	Specify	150 lbs	31
FS-3-1818-18RL	90"	24"	18" x 18"	18"	2	Both	170 lbs	52
FS-3-1824	59"	30"	18" x 24"	0	0	None	158 lbs	36
FS-3-1824-18R or L	74.5"	30"	18" x 24"	18"	1	Specify	174 lbs	46
FS-3-1824-24R or L	80.5"	30"	18" x 24"	24"	1	Specify	187 lbs	49
FS-3-1824-18RL	90"	30"	18" x 24"	18"	2	Both	310 lbs	54
FS-3-1824-24RL	102"	30"	18" x 24"	24"	2	Both	375 lbs	61
FS-3-2024	65"	30"	20" x 24"	0	0	None	165 lbs	40
FS-3-2024-24R or L	86.5"	30"	20" x 24"	24"	1	Specify	182 lbs	52
FS-3-2024-24RL	108"	30"	20" x 24"	24"	2	Both	198 lbs	64
† FS-3-2424	77"	30"	24" x 24"	0	0	None	329 lbs	47
† FS-3-2424-18R or L	92.5"	30"	24" x 24"	18"	1	Specify	353 lbs	56
† FS-3-2424-24R or L	98.5"	30"	24" x 24"	24"	1	Specify	369 lbs	59
† FS-3-2424-18RL	108"	30"	24" x 24"	18"	2	Both	382 lbs	64
† FS-3-2424-24RL	120"	30"	24" x 24"	24"	2	Both	405 lbs	71

† Requires Two Faucets

