


8" Heavy Duty, Industrial Grade, Ergonomically Designed Centrifugal Blowers for *Non-Hazardous Locations*

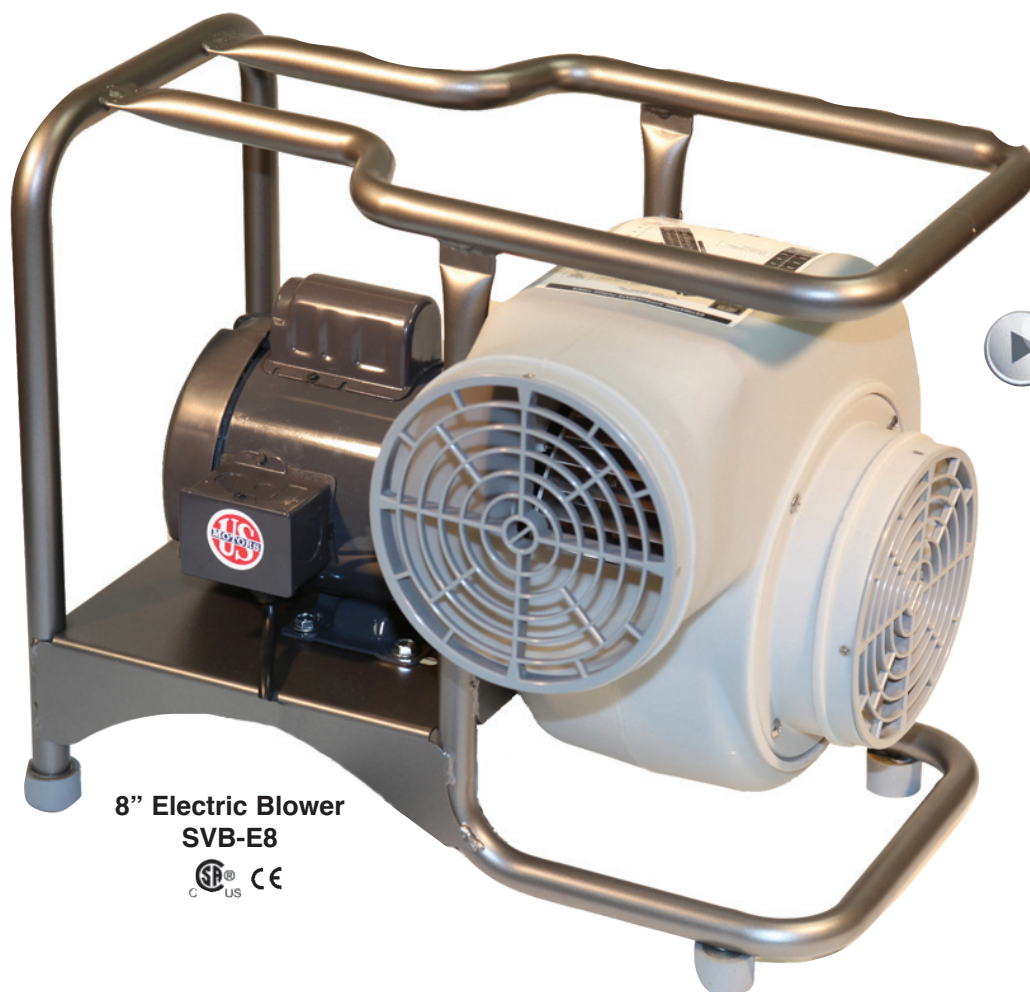

8" Electric Blower
SVB-E8



Model	Model No.	Speed	Free Air	25' 1-90° Bend	25' 2-90° Bends
Economy Blower	SVB-E8EC	1 Speed	1390 CFM	931 CFM	779 CFM
Standard Blower	SVB-E8	1 Speed	1570 CFM	1047 CFM	873 CFM
Standard Blower (50 Hz)	SVB-E850	1 Speed	1308 CFM	873 CFM	728 CFM
2-Speed Blower	SVB-E8-2	High	1570 CFM	1047 CFM	873 CFM
		Low	750 CFM	490 CFM	425 CFM
Gasoline Blower	SVB-G8	High	3000 CFM	1725 CFM	1295 CFM
		Low	1500 CFM	1040 CFM	870 CFM

Key Details:

- 8" intake and exhaust
- Non-sparking aluminum blower wheel
- Polyethylene fan housing & safety guards
- Molded polyethylene safety guards
- Powder coated tubular steel frame, dual handles

Applications

- Confined Space Entry
- Tank Entry
- Sewer Repair
- Construction & Maintenance