



Heavy-Duty Industrial Spot Coolers - 208/230/460V

Pedestal, Wall, I-Beam & Ceiling Mount Fans Non-Oscillating



**1 Year Warranty - Ultra High Velocity Air Flow
FEATURES**

- Heavy Gauge Galvanized Steel Propeller for Severe Conditions
- 4 Mounting Options - Pedestal, Wall, I-Beam & Ceiling
- 208/230/460V, 1 HP, 3 Phase, Totally Enclosed, Ball Bearing Motor
- Single Speed

PERFORMANCE 208/230/460V

Prop Dia.	CFM	RPM	Motor No.	F.L. Amps
24"	7700	1140	1369	4.0/2.0
30"	12400	1125	1369	4.0/2.0

Performance Ratings are conducted in accordance with AMCA Standard 230-99.



EDP No.	Catalog No.	Prop Dia.	Fan Style	HP	Ship Wt.	List Price
20750K	24HF36	24"	Pedestal Fan: includes 21152 (Pedestal), 21166 (Base)	1	89	\$1,578
20770K	24HW36	24"	Wall Mount Fan: includes 21187 (Tilted Wall Brkt. with Safety Cable)	1	68	\$1,424
20790K	24HI36	24"	I-Beam Mount Fan: includes 21191 (I-Beam Brkt. with Safety Cable)	1	68	\$1,503
20780K	24HS36	24"	Ceiling Mount Fan: includes 21203 (Ceiling Kit with Safety Cable)	1	58	\$1,389

All 24" Kitted Components consist of: 21050 (Motor); 21070 (Guard Assembly); 21120 (Prop); plus mounting listed above

Unit Packs Models - 1369 Motor

Motor, Specified Mounting, Propeller & Guard Shipped in Single Carton

EDP No.	Catalog No.	Prop Dia.	Fan Style	HP	Ship Wt.	List Price
20840	30HF36	30"	Pedestal Fan	1	96	\$1,658
20860	30HW36	30"	Wall Mount Fan	1	83	\$1,503
20880	30HI36	30"	I-Beam Mount Fan	1	83	\$1,583
20870	30HS36	30"	Ceiling Mount Fan	1	65	\$1,468



MOTOR TILT ADJUSTMENTS

TYPE	TILT (IN DEGREES) NON-OSCILLATING	
	UP	DOWN
FLOOR	20°	10°
WALL	20°	15°
I-BEAM	20°	20°
CEILING	8°	20°

0° = Horizontal Plane

Ceiling Mount: A safety cable kit is included in all overhead mounted air circulators to prevent the fan from falling if accidentally struck or mounting fails. Single safety cable kits consist of 12 feet of 1/16" diameter cable, 2 cable clamps and instructions.

Ultra High Velocity Air Flow

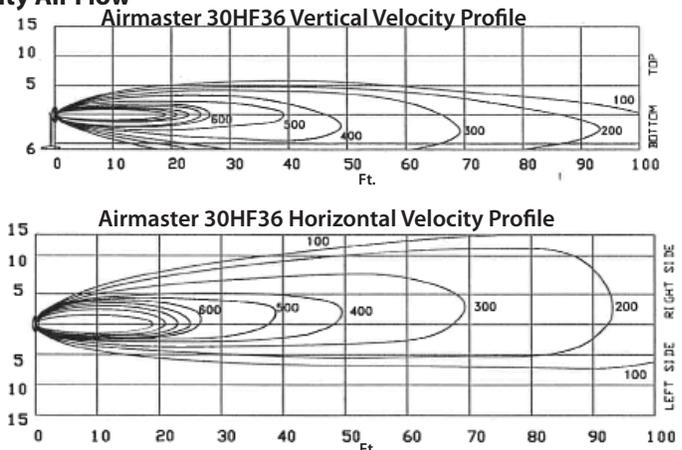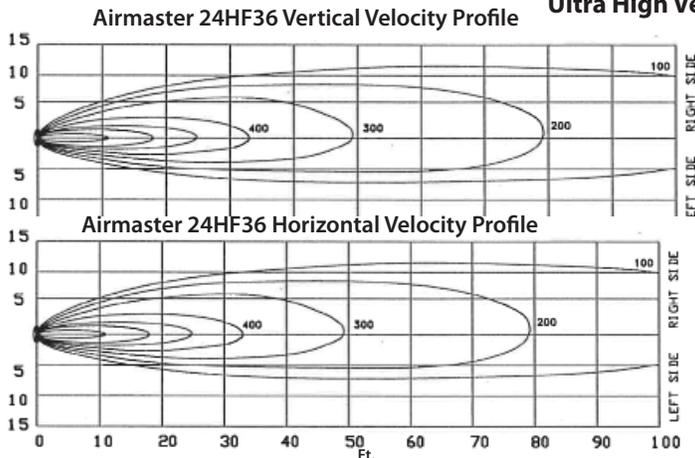

Note: Velocity is shown in FPM (Feet Per Minute), divide FPM by 88 for MPH (Miles Per Hour).

NOTES: "K" suffix indicates unit shipped as individual component parts. May be shipped UPS or Truck.

CORD AND PLUG NOT PROVIDED WITH INDUSTRIAL SPOT COOLER. Must be hard wired. Wiring must conform to all national, state and local codes.

Submission sheets available at www.airmasterfan.com