

AkroBins®

- Separate look-alike/sound-alike medications using different colors of bins
- Multiple sizes and colors allow **color coding** (vertically and horizontally) and **easy identification** of supplies
- Molded of industrial-grade polymers
- Bins sit on shelves or hang from Akro-Mils panels, racks, rails and carts
- AkroBins stack securely to optimize shelf space
- Wide hopper fronts ensure easy access
- Available in 9 colors including Clear



30250SCAR




30230STONE



Lengthwise dividers
keep items separated



"See-through" clear **bin lids** protect contents

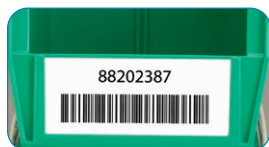

Large **front label slot** for easy coding and scanning



30237 fits perfectly on 18" deep shelving for a two-bin Kanban system. See page 24 for more details.



AWS184830260G
AkroBin Wire System



AkroBins	Outside Dimensions (In.)			Capacity/Quantity		Accessories				
Model No.	L	W	H	Bin Load Cap. On Rack	Bin Ctn. Qty.	Black Length Dividers**	Width Dividers**	Divider Pkg. Qty.	Bin Lids***	Lid Pkg. Qty.
30210*	5-3/8	4-1/8	3	10 lbs.	24	40210 (1)	—	6	30211CRY	24
30220*	7-3/8	4-1/8	3	10 lbs.	24	40220 (1)	—	6	30221CRY	24
30237	9-1/4	6	5	20 lbs.	12	40237 (1)	—	6	—	—
30224	10-7/8	4-1/8	4	20 lbs.	12	40224 (1)	—	6	30225CRY	12
30230*	10-7/8	5-1/2	5	30 lbs.	12	40230 (1)	41230 (3)	6	30231CRY	12
30234	14-3/4	5-1/2	5	50 lbs.	12	40234 (1)	—	6	—	—
30239	10-7/8	8-1/4	7	50 lbs.	6	40239 (1)	—	6	—	—
30240*	14-3/4	8-1/4	7	60 lbs.	12	40245 (1)	—	6	—	—
30265	18	8-1/4	9	60 lbs.	6	40265 (1)	—	6	—	—
30235	10-7/8	11	5	50 lbs.	6	40230 (3)	—	6	30236CRY	6
30260	18	11	10	60 lbs.	6	40260 (3)	—	6	—	—
30255	10-7/8	16-1/2	5	60 lbs.	6	40230 (3)	—	6	—	—
30250*	14-3/4	16-1/2	7	75 lbs.	6	40245 (3)	41250 (3)	6	—	—
30270	18	16-1/2	11	75 lbs.	3	40270 (3)	41270 (3)	6	—	—
30320	8-5/8	33	5	80 lbs.	4	40321 & 40220 (7)	—	7/6	—	4

Order in carton quantities. One color per carton: Specify Red, Blue, Yellow, Stone, Clear, Green or Black. *Available in Purple and Light Blue. Other colors available, minimum quantities apply. CAUTION: When using bins with hanging systems, do not exceed the weight capacity for the rack, which may be less than the total sum of bin capacities. 40321=Full Divider; 40220=Short Divider. **() = Max. # of dividers per bin. ***Assembly required.

AkroBin Wire Systems			Shelf Dimensions (In.)			Quantity	
Model No.	Description	Available Colors	D	L	H	# of Bins	Shelves
AWS143630320	Wire Shelving w/ 30320 Bins	B, R, Y, S, SC	14	36	74	12‡	11
AWS143630240	Wire Shelving w/ 30240 Bins	B, R, Y, G, K, S, SC	14	36	74	36	4
AWS143630250	Wire Shelving w/ 30250 Bins	B, R, Y, G, K, S, SC	14	36	74	18	4
AWS184830260	Wire Shelving w/ 30260 Bins	B, R, Y, G, K, S, SC	18	48	74	24‡	6
AWS183630265	Wire Shelving w/ 30265 Bins	B, R, Y, G, K, S, SC	18	36	74	18‡	5
AWS183630270	Wire Shelving w/ 30270 Bins	B, R, Y, G, K, S, SC	18	36	74	9‡	5

Bin color code: R=Red, B=Blue, Y=Yellow, G=Green, K=Black, S=Stone, SC=Clear. Specify one bin color when ordering. ‡Bonus bins included.

