




LENGTHS (CONTINUED)

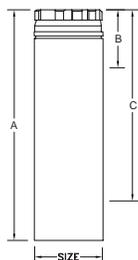


Adjustable Length - Round

- Adjustable lengths telescope into standard AmeriVent pipe sections to reach desired length

| PART # | PIPE SIZE | ADJ LENGTH | EXTENSION FROM B | LENGTH TO C |
|--------|-----------|------------|------------------|-------------|
| 3E12A | 3" | 12" | 3" | 10" |
| 4E12A | 4" | 12" | 3" | 10" |
| 5E12A | 5" | 12" | 3" | 10" |
| 6E12A | 6" | 12" | 3" | 10" |
| 7R12A | 7" | 12" | 3" | 10" |
| 8R12A | 8" | 12" | 3" | 10" |
| 9R18A | 9" | 18" | 3" | 16" |
| 10R18A | 10" | 18" | 3" | 16" |
| 12R18A | 12" | 18" | 3" | 16" |
| 14R18A | 14" | 18" | 5" | 16" |
| 16R18A | 16" | 18" | 5" | 16" |
| 18R18A | 18" | 18" | 5" | 16" |
| 20R18A | 20" | 18" | 5" | 16" |
| 22R18A | 22" | 18" | 5" | 16" |
| 24R18A | 24" | 18" | 5" | 16" |
| 26R18A | 26" | 18" | 5" | 16" |
| 28R18A | 28" | 18" | 5" | 16" |
| 30R18A | 30" | 18" | 5" | 16" |

ELBOWS

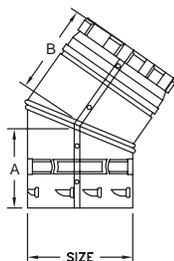

45° Elbow - Round

- Used to offset installation to avoid obstructions such as rafters & joists
- Size 3" through 14" adjust easily from 0° to 45°
- Sizes 16" through 30" are non-adjustable
- See the Gas Vent Offset Chart

PART #

SIZE

A

B

0° to 45° Adjustable

| | | | |
|-------|-----|----------|----------|
| 3E45 | 3" | 3" | 2 3/4" |
| 4E45 | 4" | 3 1/8" | 3 1/16" |
| 5E45 | 5" | 3 1/2" | 3 1/2" |
| 6E45 | 6" | 4" | 3 13/16" |
| 7R45 | 7" | 4 15/16" | 4 1/4" |
| 8R45 | 8" | 4 3/4" | 4 9/16" |
| 9R45 | 9" | 5" | 5 3/8" |
| 10R45 | 10" | 5 7/8" | 5 3/8" |
| 12R45 | 12" | 6" | 5 3/8" |
| 14R45 | 14" | 6 5/8" | 6 1/2" |

Non-Adjustable

| | | | |
|-------|-----|--------|----------|
| 16R45 | 16" | 7" | 7" |
| 18R45 | 18" | 7 1/2" | 7 1/2" |
| 20R45 | 20" | 8" | 7 5/8" |
| 22R45 | 22" | 8 1/2" | 8 5/8" |
| 24R45 | 24" | 8 5/8" | 8 15/16" |
| 26R45 | 26" | 9" | 9" |
| 28R45 | 28" | 9 1/2" | 9 1/2" |
| 30R45 | 30" | 10" | 10" |