




TYPE B GAS VENT ~ ROUND

LENGTHS

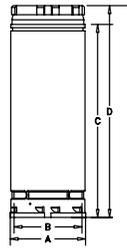

Lengths - Round

- Made of corrosion-resistant galvanized steel and aluminum double-wall construction
- Snap-lock coupling for easy installation

PART #	SIZE	A - O.D.	B - I.D.	C	D
3E6	3"	3 1/2"	3"	5"	6"
3E12	3"	3 1/2"	3"	11"	12"
3E18	3"	3 1/2"	3"	17"	18"
3E24	3"	3 1/2"	3"	23"	24"
3E3	3"	3 1/2"	3"	35"	36"
3E4	3"	3 1/2"	3"	47"	48"
3E5	3"	3 1/2"	3"	59"	60"
4E6	4"	4 1/2"	4"	5"	6"
4E12	4"	4 1/2"	4"	11"	12"
4E18	4"	4 1/2"	4"	17"	18"
4E24	4"	4 1/2"	4"	23"	24"
4E3	4"	4 1/2"	4"	35"	36"
4E4	4"	4 1/2"	4"	47"	48"
4E5	4"	4 1/2"	4"	59"	60"
5E6	5"	5 1/2"	5"	5"	6"
5E12	5"	5 1/2"	5"	11"	12"
5E18	5"	5 1/2"	5"	17"	18"
5E24	5"	5 1/2"	5"	23"	24"
5E3	5"	5 1/2"	5"	35"	36"
5E4	5"	5 1/2"	5"	47"	48"
5E5	5"	5 1/2"	5"	59"	60"
6E6	6"	6 1/2"	6"	5"	6"
6E12	6"	6 1/2"	6"	11"	12"
6E18	6"	6 1/2"	6"	17"	18"
6E24	6"	6 1/2"	6"	23"	24"
6E3	6"	6 1/2"	6"	35"	36"
6E4	6"	6 1/2"	6"	47"	48"
6E5	6"	6 1/2"	6"	59"	60"
7R6	7"	8"	7"	5"	6"
7R12	7"	8"	7"	11"	12"
7R18	7"	8"	7"	17"	18"
7R24	7"	8"	7"	23"	24"
7R3	7"	8"	7"	35"	36"
7R4	7"	8"	7"	47"	48"
7R5	7"	8"	7"	59"	60"
8R6	8"	9"	8"	5"	6"
8R12	8"	9"	8"	11"	12"
8R18	8"	9"	8"	17"	18"
8R24	8"	9"	8"	23"	24"
8R3	8"	9"	8"	35"	36"
8R5	8"	9"	8"	59"	60"

PART #	SIZE	A - O.D.	B - I.D.	C	D
9R12	9"	10"	9"	11"	12"
9R18	9"	10"	9"	17"	18"
9R24	9"	10"	9"	23"	24"
9R3	9"	10"	9"	35"	36"
10R12	10"	11"	10"	11"	12"
10R18	10"	11"	10"	17"	18"
10R24	10"	11"	10"	23"	24"
10R3	10"	11"	10"	35"	36"
12R12	12"	13"	12"	11"	12"
12R18	12"	13"	12"	17"	18"
12R24	12"	13"	12"	23"	24"
12R3	12"	13"	12"	35"	36"
14R12	14"	15"	14"	11"	12"
14R18	14"	15"	14"	17"	18"
14R24	14"	15"	14"	23"	24"
14R3	14"	15"	14"	35"	36"
16R12	16"	17"	16"	11"	12"
16R18	16"	17"	16"	17"	18"
16R24	16"	17"	16"	23"	24"
16R3	16"	17"	16"	35"	36"
18R12	18"	19"	18"	11"	12"
18R18	18"	19"	18"	17"	18"
18R24	18"	19"	18"	23"	24"
18R3	18"	19"	18"	35"	36"
20R12	20"	21"	20"	11"	12"
20R18	20"	21"	20"	17"	18"
20R24	20"	21"	20"	23"	24"
20R3	20"	21"	20"	35"	36"
22R12	22"	23"	22"	11"	12"
22R18	22"	23"	22"	17"	18"
22R24	22"	23"	22"	23"	24"
22R3	22"	23"	22"	35"	36"
24R12	24"	25"	24"	11"	12"
24R18	24"	25"	24"	17"	18"
24R24	24"	25"	24"	23"	24"
24R3	24"	25"	24"	35"	36"
26R12	26"	27"	26"	11"	12"
26R18	26"	27"	26"	17"	18"
26R24	26"	27"	26"	23"	24"
26R3	26"	27"	26"	35"	36"
28R12	28"	29"	28"	11"	12"
28R18	28"	29"	28"	17"	18"
28R24	28"	29"	28"	23"	24"
28R3	28"	29"	28"	35"	36"
30R12	30"	31"	26"	11"	12"
30R18	30"	31"	26"	17"	18"
30R24	30"	31"	26"	23"	24"
30R3	30"	31"	26"	35"	36"