


AS 2528     EG,  GR


**TROLLEY BEAM STANDARD SUPPORT**

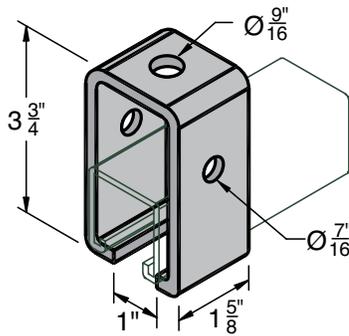

Std Pkg 10 - Wt./100 pcs: 107 Lbs.

AS 2528-1     EG,  GR

**TROLLEY BEAM JOINT SUPPORT**


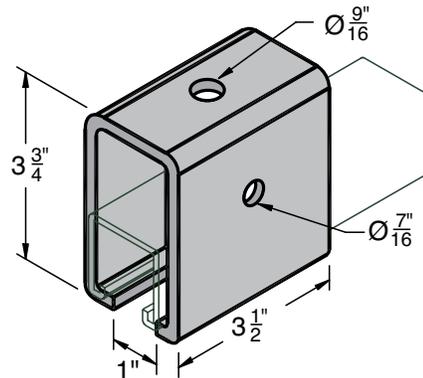


Std Pkg 10 - Wt./100 pcs: 233 Lbs.

AS 2521     EG

**TWO WHEEL TROLLEY**

Use With AS 200.

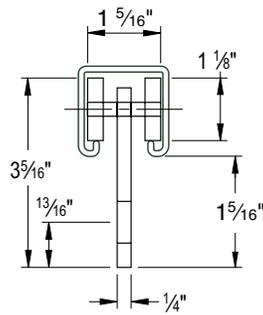
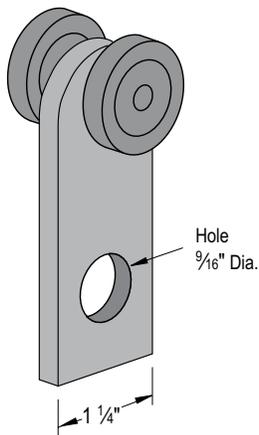


Stainless Steel Ball Bearings  
\* Based on standard dimensions for channel  
Std Pkg: 20 · Wt./100 pcs: 46 lbs.

AS 2522     EG

**FOUR WHEEL TROLLEY**

Use With AS 200.

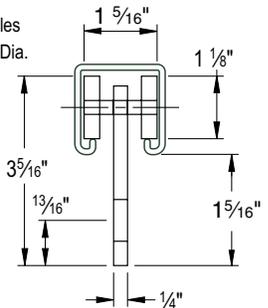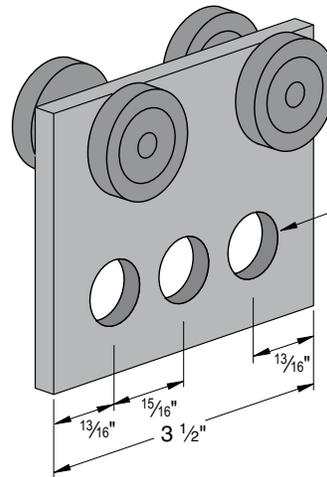

Stainless Steel Ball Bearings  
\* Based on standard dimensions for channel  
Std Pkg: 10 · Wt./100 pcs: 110 lbs.

**LEGEND:**

**GR:** Powder Coated Supr-Green    **EG:** Electro-Galvanized    **PG:** Pre-Galvanized    **AL:** Aluminum    **HG:** Hot Dipped Galvanized    **PL:** Plain    **SS:** Stainless Steel    **ZTC:** Zinc Trivalent Chromium  
Stainless Steel (**SS**), Zinc Trivalent Chromium (**ZTC**) and Hot Dipped Galvanized (**HG**) are specialty finishes. Pricing is located in the Specialty Strut Section of the Anvil-Strut price book.

| PROJECT INFORMATION |  | APPROVAL STAMP                             |  |
|---------------------|--|--|--|
| Project:            |  | <input type="checkbox"/> Approved          |  |
| Address:            |  | <input type="checkbox"/> Approved as noted |  |
| Contractor:         |  | <input type="checkbox"/> Not approved      |  |
| Engineer:           |  | Remarks:                                   |  |
| Submittal Date:     |  |  |  |
| Notes 1:            |  |  |  |
| Notes 2:            |  |  |  |