
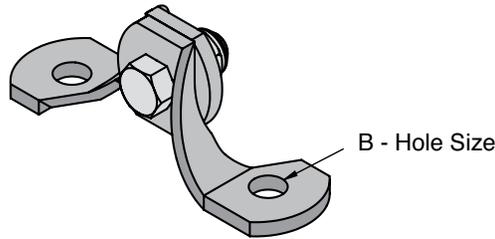


AS 9402 EG

2-HOLE HINGE CONNECTOR


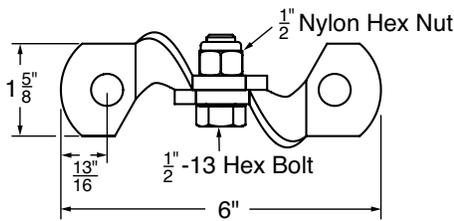


B	Wt./ 100 Pcs.
1/2"	90
5/8"	88
3/4"	86

Std Pkg 15 - Wt/100 pcs: See chart above.

AS 9403 EG

3-HOLE HINGE CONNECTOR

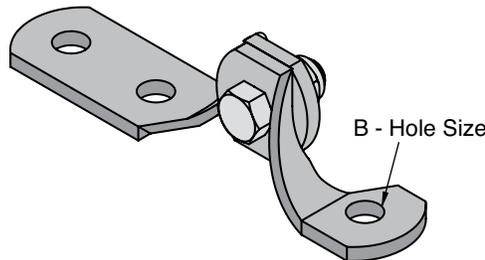
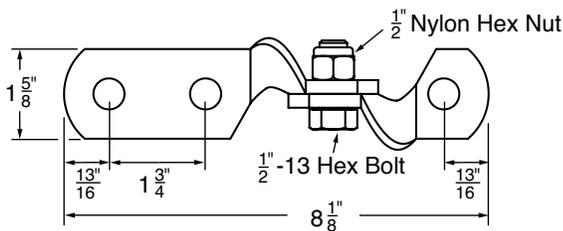


B	Wt./ 100 Pcs.
1/2"	108
5/8"	107
3/4"	106

Std Pkg 15 - Wt/100 pcs: See chart above.

AS 9404 EG

4-HOLE HINGE CONNECTOR

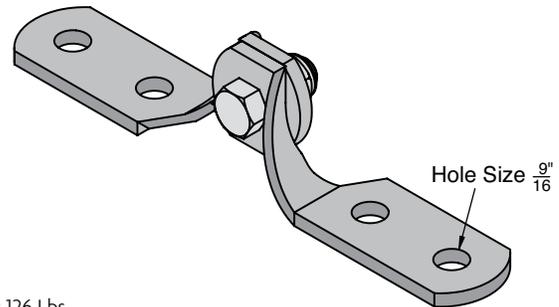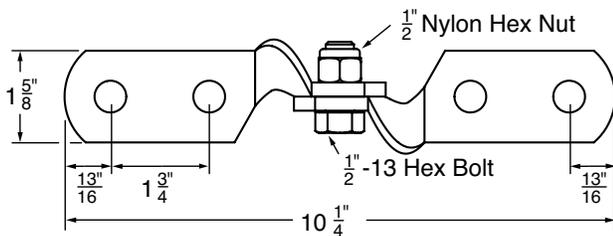

Std Pkg 10 - Wt/100 pcs: 126 Lbs.

Page notes unless otherwise specified: 1/4" thick, 1 5/8" wide, holes 9/16" diameter, spaced 1 7/8" on center and 1 3/4" from end.

LEGEND:

GR: Powder Coated Supr-Green EG: Electro-Galvanized PG: Pre-Galvanized AL: Aluminum HG: Hot Dipped Galvanized PL: Plain SS: Stainless Steel ZTC: Zinc Trivalent Chromium
Stainless Steel (SS), Zinc Trivalent Chromium (ZTC) and Hot Dipped Galvanized (HG) are specialty finishes. Pricing is located in the Specialty Strut Section of the Anvil-Strut price book.

PROJECT INFORMATION		APPROVAL STAMP	
Project:		<input type="checkbox"/> Approved	
Address:		<input type="checkbox"/> Approved as noted	
Contractor:		<input type="checkbox"/> Not approved	
Engineer:		Remarks:	
Submittal Date:			
Notes 1:			
Notes 2:			