


AS 748 EG, GR


4-HOLE JOINT CORNER CONNECTOR

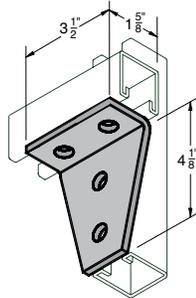

Std Pkg 25 - Wt/100 pcs: 102 Lbs.

AS 614 EG, GR


4-HOLE JOINT CORNER CONNECTOR

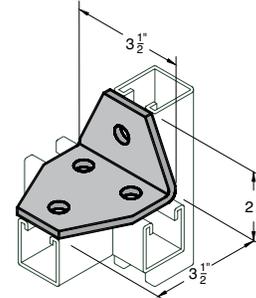

Std Pkg 25 - Wt/100 pcs: 101 Lbs.

AS 615 EG, GR


5-HOLE SHELF JOINT ANGLE

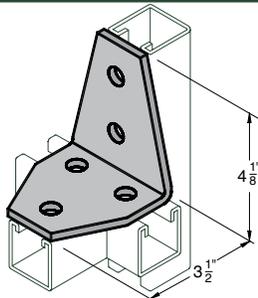

Std Pkg 10 - Wt/100 pcs: 135 Lbs.

AS 927 EG, GR


5-HOLE CORNER CONNECTOR

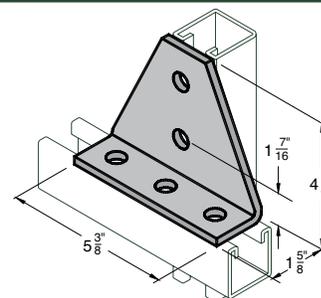

Std Pkg 10 - Wt/100 pcs: 141 Lbs.

AS 689 EG, GR

ADJUSTABLE DOUBLE SLOTTED CORNER CONNECTOR

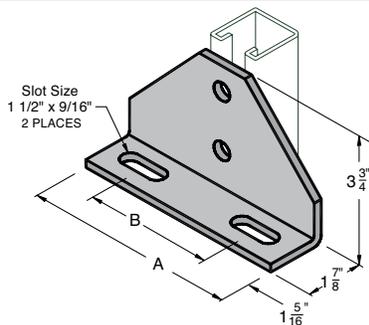

Std Pkg: 10 · Wt/100 pcs: See chart above.

Catalog No.	A	B	Wt./100 Pcs.
AS 689 A	6 ⁵ / ₈ "	4"	180
AS 689 B	8 ⁵ / ₈ "	6"	256

Page notes unless otherwise specified: 1/4" thick, 1 5/8" wide, holes 9/16" diameter, spaced 1 7/8" on center and 1 3/16" from end.

LEGEND:

GR: Powder Coated Supr-Green EG: Electro-Galvanized PG: Pre-Galvanized AL: Aluminum HG: Hot Dipped Galvanized PL: Plain SS: Stainless Steel ZTC: Zinc Trivalent Chromium
Stainless Steel (SS), Zinc Trivalent Chromium (ZTC) and Hot Dipped Galvanized (HG) are specialty finishes. Pricing is located in the Specialty Strut Section of the Anvil-Strut price book.

PROJECT INFORMATION		APPROVAL STAMP
Project:		<input type="checkbox"/> Approved
Address:		<input type="checkbox"/> Approved as noted
Contractor:		<input type="checkbox"/> Not approved
Engineer:		Remarks:
Submittal Date:		
Notes 1:		
Notes 2:		