


AS 2520 EG, GR


TWO HOLE ADJUSTMENT ANGLE

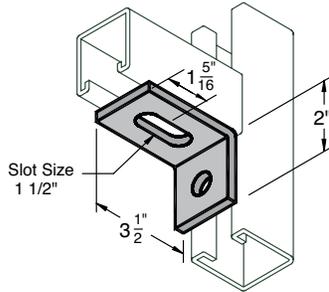

Std Pkg 25 - Wt./100 pcs: 42 Lbs.

AS 2545 EG, GR


SLOTTED 90° ANGLE

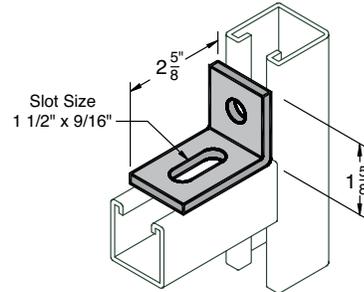

Std Pkg 50 - Wt./100 pcs: 38 Lbs.

AS 3049 EG, GR


2-HOLE SLOTTED 90° CORNER CONNECTOR

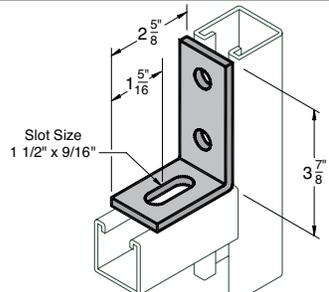

Std Pkg 25 - Wt./100 pcs: 66 Lbs.

AS 793 EG, GR

4-HOLE CLOSED ANGLE CONNECTOR

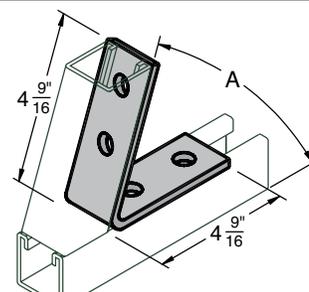


Std Pkg 25 - Wt./100 pcs: 100 Lbs.

A
37½°
45°
52½°
60°
67½°
75°
82½°

AS 763, AS 764 EG, GR

SLOTTED ADJUSTMENT CORNER ANGLE

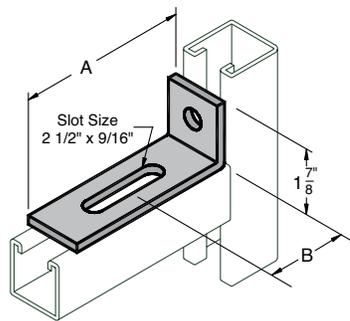

Std Pkg: 25 - Wt./100 pcs: See chart above.

Catalog No.	A	B	Wt./100 Pcs.
AS 763	4 7/16"	2 1/2"	58
AS 764	6 7/8"	4 1/2"	85

Page notes unless otherwise specified: 1/4" thick, 15/8" wide, holes 9/16" diameter, spaced 1 7/8" on center and 1 3/16" from end.

LEGEND:

GR: Powder Coated Supr-Green EG: Electro-Galvanized PG: Pre-Galvanized AL: Aluminum HG: Hot Dipped Galvanized PL: Plain SS: Stainless Steel ZTC: Zinc Trivalent Chromium
Stainless Steel (SS), Zinc Trivalent Chromium (ZTC) and Hot Dipped Galvanized (HG) are specialty finishes. Pricing is located in the Specialty Strut Section of the Anvil-Strut price book.

PROJECT INFORMATION		APPROVAL STAMP	
Project:		<input type="checkbox"/> Approved	
Address:		<input type="checkbox"/> Approved as noted	
Contractor:		<input type="checkbox"/> Not approved	
Engineer:		Remarks:	
Submittal Date:			
Notes 1:			
Notes 2:			