


ONE PIECE CABLE AND CONDUIT CLAMP

- AS 3101 EG
- AS 3102 EG
- AS 3103 EG
- AS 3104 EG
- AS 3105 EG
- AS 3106 EG
- AS 3107 EG
- AS 3108 EG
- AS 3109 EG
- AS 3110 EG
- AS 3111 EG
- AS 3112 EG
- AS 3113 EG
- AS 3114 EG

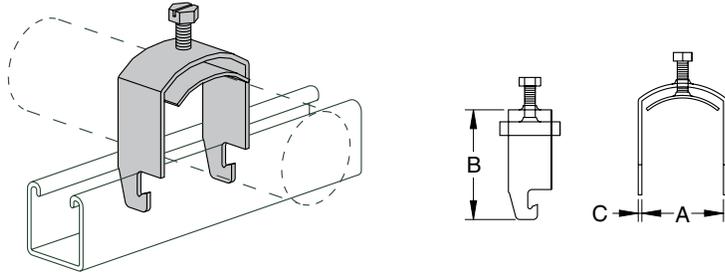

No.	Size	A	B	C	Std Pkg	Wt/100 pcs
AS 3101	3/8"	7/16"	1 5/8"	14	100	6
AS 3102	1/2"	9/16"	1 3/4"	14	100	7
AS 3103	3/4"	1 3/16"	2"	14	100	12
AS 3104	1"	1 1/16"	2 1/4"	14	100	15
AS 3105	1 1/4"	1 5/16"	2 1/2"	14	100	19
AS 3106	1 1/2"	1 9/16"	2 3/4"	14	100	20
AS 3107	1 3/4"	1 13/16"	3"	12	100	25
AS 3108	2"	2 1/16"	3 1/4"	12	100	35
AS 3109	2 3/8"	2 7/16"	3 5/8"	12	75	41
AS 3110	2 3/4"	2 13/16"	4"	12	75	60
AS 3111	3 1/4"	3 5/16"	4 1/2"	12	75	64
AS 3112	3 3/4"	3 13/16"	5"	12	50	91
AS 3113	4"	4 1/16"	5 1/4"	12	40	100
AS 3114	4 3/8"	4 7/16"	5 5/8"	12	30	115

Std Pkg & Wt/100 pcs: See chart above.

LEGEND:

GR: Powder Coated Supr-Green **EG:** Electro-Galvanized **PG:** Pre-Galvanized **AL:** Aluminum **HG:** Hot Dipped Galvanized **PL:** Plain **SS:** Stainless Steel **ZTC:** Zinc Trivalent Chromium
 Stainless Steel (SS), Zinc Trivalent Chromium (ZTC) and Hot Dipped Galvanized (HG) are specialty finishes. Pricing is located in the Specialty Strut Section of the Anvil-Strut price book.

PROJECT INFORMATION		APPROVAL STAMP	
Project:		<input type="checkbox"/> Approved	
Address:		<input type="checkbox"/> Approved as noted	
Contractor:		<input type="checkbox"/> Not approved	
Engineer:		Remarks:	
Submittal Date:			
Notes 1:			
Notes 2:			