


AS 922     EG,  GR,  ZTC


### RH & LH 2-HOLE SINGLE CORNER ANGLE CONNECTOR

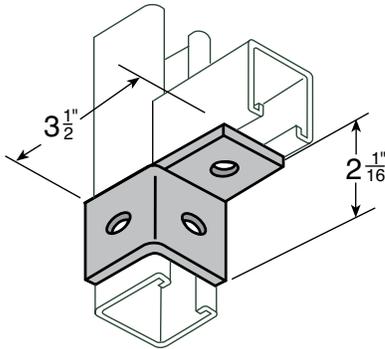

When ordering, Specify RH or LH  
Std Pkg 20 - Wt/100 pcs: 60 Lbs.

AS 2128     EG,  GR


### RH & LH 6-HOLE CORNER CONNECTOR

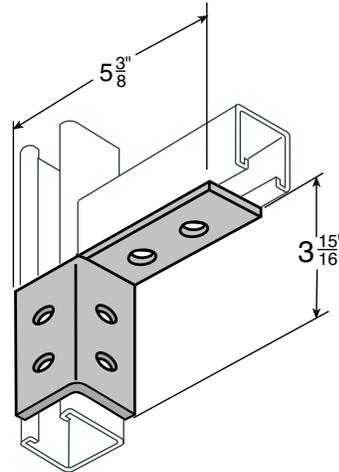

When ordering, Specify RH or LH  
Std Pkg 10 - Wt/100 pcs: 119 Lbs.

AS 665     EG,  GR,  ZTC


### 4-HOLE DOUBLE CORNER CONNECTOR

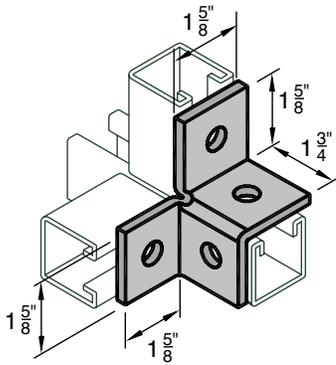

Std Pkg 25 - Wt/100 pcs: 76 Lbs.

AS 667     EG,  GR,  ZTC

### 8-HOLE DOUBLE CORNER CONNECTOR

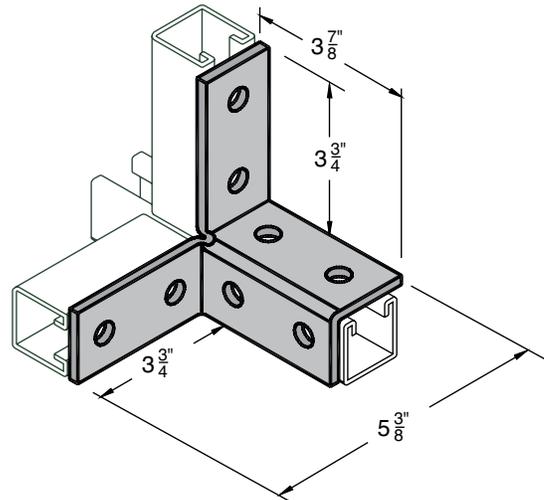

Std Pkg 10 - Wt/100 pcs: 155 Lbs.

**Page notes unless otherwise specified:** 1/4" thick, 1 5/8" wide, holes 9/16" diameter, spaced 1 7/8" on center and 1 3/4" from end.

**LEGEND:**

**GR:** Powder Coated Supr-Green    **EG:** Electro-Galvanized    **PG:** Pre-Galvanized    **AL:** Aluminum    **HG:** Hot Dipped Galvanized    **PL:** Plain    **SS:** Stainless Steel    **ZTC:** Zinc Trivalent Chromium  
Stainless Steel (**SS**), Zinc Trivalent Chromium (**ZTC**) and Hot Dipped Galvanized (**HG**) are specialty finishes. Pricing is located in the Specialty Strut Section of the Anvil-Strut price book.

PROJECT INFORMATION		APPROVAL STAMP
Project:		<input type="checkbox"/> Approved
Address:		<input type="checkbox"/> Approved as noted
Contractor:		<input type="checkbox"/> Not approved
Engineer:		Remarks:
Submittal Date:		
Notes 1:		
Notes 2:		