


HBS-Standard-Base Only

HBS-BASE RUBBER SUPPORT – BASE ONLY

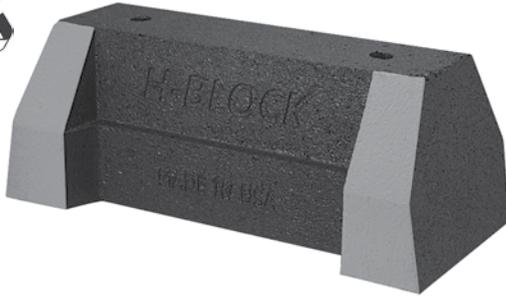


The HBS-Base Series is UV resistant and suitable for installation on most types of roofing material or other flat surfaces. Can be used as a curb (sleeper) replacement. Screw fasteners can be used to attach one or two hole pipe straps or a piece of strut (not included).

Specifications – H-Block Support
Material - 100% recycled rubber, UV resistant



Base Area
Shown = 33.1 Sq. In.
For use in bearing calculations

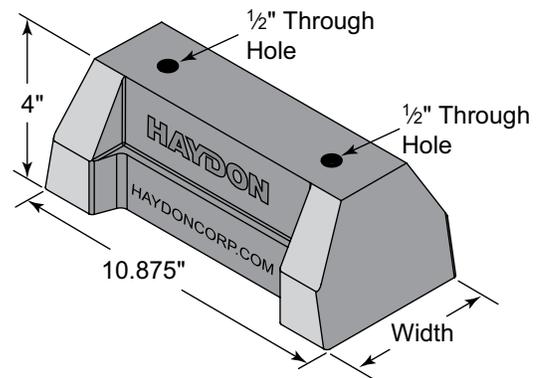

HBS-BASE RUBBER SUPPORT – BASE ONLY

Model No.	Height	Width	Base Length	Weight (Lbs)	Uniform Load Capacity (Lbs) *
HBS-Standard-Base Only	4" (101mm)	5" (127mm)	10 7/8" (276mm)	4.80 lbs.	1,500*

* This load is only for the capacity of the components in this assembly. Please consult roofing manufacturer or engineer for roof load capacity.

* Safety Factor of 3, load based on actual lab testing.

LEGEND:

PG: Pre-Galvanized HG: Hot Dipped Galvanized Pricing is located in the Anvil H-Block price book.

PROJECT INFORMATION		APPROVAL STAMP
Project:		<input type="checkbox"/> Approved
Address:		<input type="checkbox"/> Approved as noted
Contractor:		<input type="checkbox"/> Not approved
Engineer:		Remarks:
Submittal Date:		
Notes 1:		
Notes 2:		