


## HBS-DSFW Fixed Width Duct Support PG, HG

### HBS-DS DUCT SUPPORT SERIES WITH FIXED WIDTH AND ADJUSTABLE HEIGHT



The HBS-DSFW Series is designed specifically for supporting duct work.

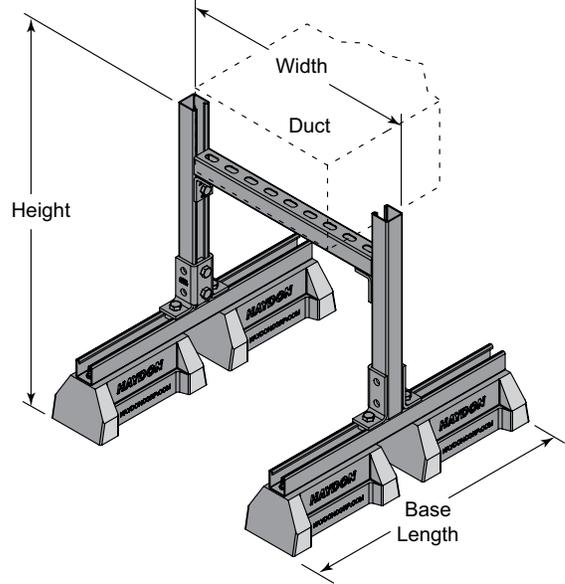

**Specifications – HBS-DSFW**  
 Fixed Width & Height.  
 All hardware required for assembly is included.  
 Base Material - 100% recycled rubber, UV resistant  
 Crossbeams - 1½" H-132-RS3 Channel

### HBS-DS DUCT SUPPORT SERIES WITH FIXED WIDTH AND ADJUSTABLE HEIGHT

Model No.	Height	Width	Base Length	No. of Bases	Weight (Lbs)	Uniform Load Capacity (Lbs) *
<input type="checkbox"/> HBS-DS2FW-23-18-H-132-PG	23" (584mm)	18" (457mm)	24" (610mm)	4	39.80	2,030*
<input type="checkbox"/> HBS-DS2FW-23-24-H-132-PG		24" (610mm)			40.67	1,520*
<input type="checkbox"/> HBS-DS2FW-23-36-H-132-PG		36" (914mm)			42.33	1,010*
<input type="checkbox"/> HBS-DS2FW-23-48-H-132-PG		48" (1219mm)			43.99	755*
<input type="checkbox"/> HBS-DS2FW-29-18-H-132-PG	29" (737mm)	18" (457mm)	24" (610mm)	4	41.58	2,030*
<input type="checkbox"/> HBS-DS2FW-29-24-H-132-PG		24" (610mm)			42.41	1,520*
<input type="checkbox"/> HBS-DS2FW-29-36-H-132-PG		36" (914mm)			44.08	1,010*
<input type="checkbox"/> HBS-DS2FW-29-48-H-132-PG		48" (1219mm)			45.74	755*
<input type="checkbox"/> HBS-DS2FW-41-18-H-132-PG	41" (1041mm)	18" (457mm)	24" (610mm)	4	45.07	2,030*
<input type="checkbox"/> HBS-DS2FW-41-24-H-132-PG		24" (610mm)			45.90	1,520*
<input type="checkbox"/> HBS-DS2FW-41-36-H-132-PG		36" (914mm)			47.56	1,010*
<input type="checkbox"/> HBS-DS2FW-41-48-H-132-PG		48" (1219mm)			49.22	755*
<input type="checkbox"/> HBS-DS3FW-53-18-H-132-PG	53" (1346mm)	18" (457mm)	36" (914mm)	6	62.23	2,030*
<input type="checkbox"/> HBS-DS3FW-53-24-H-132-PG		24" (610mm)			63.06	1,520*
<input type="checkbox"/> HBS-DS3FW-53-36-H-132-PG		36" (914mm)			64.72	1,010*
<input type="checkbox"/> HBS-DS3FW-53-48-H-132-PG		48" (1219mm)			66.38	755*

\* This load is only for the capacity of the components in this assembly. Please consult roofing manufacturer or engineer for roof load capacity

#### LEGEND:

**PG:** Pre-Galvanized **HG:** Hot Dipped Galvanized Pricing is located in the Anvil H-Block price book.

PROJECT INFORMATION		APPROVAL STAMP
<b>Project:</b>		<input type="checkbox"/> Approved
<b>Address:</b>		<input type="checkbox"/> Approved as noted
<b>Contractor:</b>		<input type="checkbox"/> Not approved
<b>Engineer:</b>		<b>Remarks:</b>
<b>Submittal Date:</b>		
<b>Notes 1:</b>		
<b>Notes 2:</b>		