

**HBM-HPC Series**


PG

**HBM-HINGED PIPE CLAMP SERIES**



Specifications – HBM-Hinged Pipe Clamp Series  
H-Block Mini Support with:  
Threaded Rod and Hinged Pipe Clamp  
Material - 100% recycled rubber, UV resistant

A cost-effective method for mounting and supporting single pipe applications without losing strength and integrity.

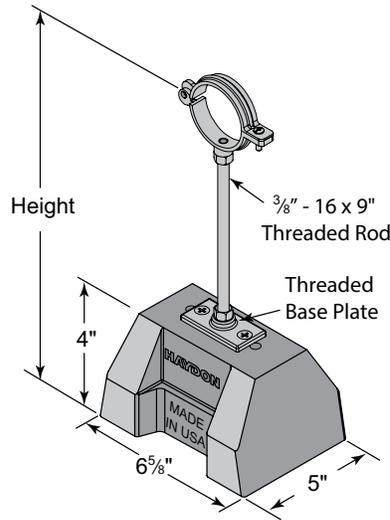

**HBM-HINGED PIPE CLAMP SERIES**

Model No.	Height	Width	Base Length	Weight (Lbs)	Uniform Load Capacity (Lbs)*
<input type="checkbox"/> HBM-HPC-1/2 IN-EG	10" - 12" (254mm - 305mm)	5" (127mm)	6 <sup>5</sup> / <sub>8</sub> " (168mm)	2.70	125 *
<input type="checkbox"/> HBM-HPC-3/4 IN-EG				2.80	
<input type="checkbox"/> HBM-HPC-1 IN-EG				2.90	
<input type="checkbox"/> HBM-HPC-1-1/4 IN-EG				3.0	
<input type="checkbox"/> HBM-HPC-1-1/2 IN-EG				3.10	
<input type="checkbox"/> HBM-HPC-2 IN-EG				3.30	

\* This load is only for the capacity of the components in this assembly. Please consult roofing manufacturer or engineer for roof load capacity

**LEGEND:**

PG: Pre-Galvanized HG: Hot Dipped Galvanized Pricing is located in the Anvil H-Block price book.

PROJECT INFORMATION		APPROVAL STAMP	
Project:		<input type="checkbox"/> Approved	
Address:		<input type="checkbox"/> Approved as noted	
Contractor:		<input type="checkbox"/> Not approved	
Engineer:		Remarks:	
Submittal Date:			
Notes 1:			
Notes 2:			