


Light Duty Two-Hole Pipe Strap Fig. 026G

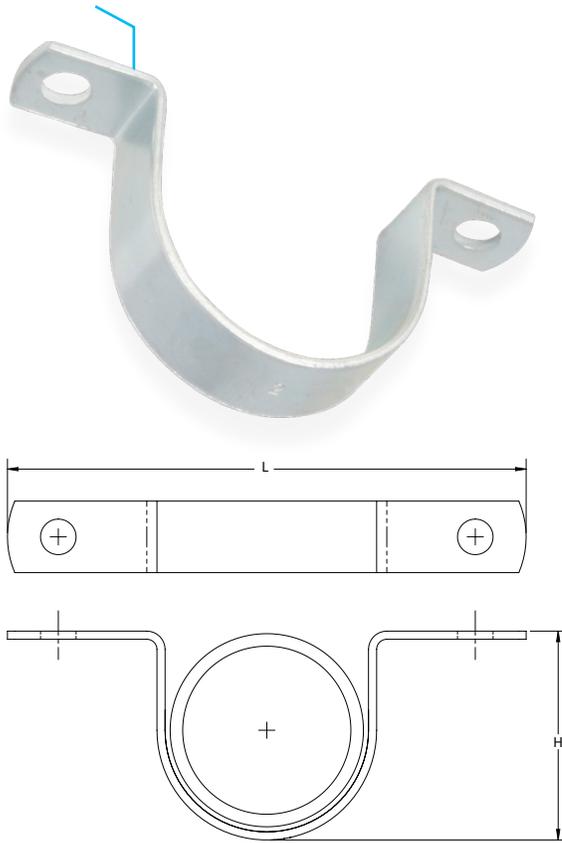

Size Range: ¼" through 4"

Material: Carbon Steel

Finish: Electro-Galvanized

Service: Recommended for the suspension of stationary NPS steel pipe.

Maximum Temperature: 450° F

Approvals: MSS SP-58 (Type-26)

Ordering: Nominal pipe size and figure number.



Fig. 026G: Dimensions (in.) Loads (lbs.) • Height/Length (in.)

Pipe Size	Max Load w/ Lag Screws	Max Load w/ Bolt to Steel	H Overall Height	Length	Bolt Hole Distance
¼"	150 lbs.	205 lbs.	5/8"	2 ¹⁵ / ₁₆ "	1.89"
½"	150 lbs.	205 lbs.	7/8"	3 ¼"	2.21"
¾"	150 lbs.	205 lbs.	1 1/8"	3 7/16"	2.44"
1"	150 lbs.	205 lbs.	1 3/8"	3 3/16"	2.76"
1 ¼"	159 lbs.	205 lbs.	1 ¾"	4 1/8"	3.07"
1 ½"	150 lbs.	205 lbs.	2"	4 3/8"	3.31"
2"	150 lbs.	205 lbs.	2 7/16"	4 13/16"	3.78"
2 ½"	225 lbs.	305 lbs.	2 5/16"	5 5/16"	4.25"
3"	225 lbs.	305 lbs.	3 9/16"	5 5/16"	4.88"
4"	225 lbs.	305 lbs.	4 9/16"	7"	5.91"

PROJECT INFORMATION	APPROVAL STAMP
Project:	Approved
Address:	Approved as noted
Contractor:	Not approved
Engineer:	Remarks:
Submittal Date:	
Notes 1:	
Notes 2:	