

35-200 SERIES COMPRESSION BIBB FAUCET




Features heavy pattern with large flow path.

FEATURES

- Solid Bronze Construction
- 3/4" Hose Connection
- Aluminum Handwheel
- Made in USA

PART NUMBER	PIPE SIZE (IN.)	WT./100 (LB.)
35-201-01	1/2	58.3
35-202-01	3/4	57.0

31-200/31-500 SERIES 90° DRAIN VALVE

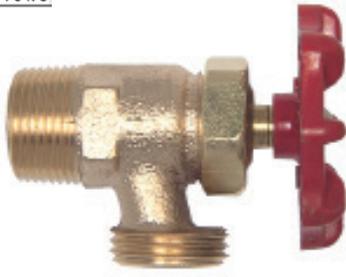

For deluxe water heaters and low pressure boilers.

FEATURES

- Maximum Rated Pressure: 200 psig
- Maximum Rated Temperature: 250°F
- Red Aluminum Wheel Handle
- 31-200 Series Heavy Pattern, 3/4" MNPT Inlet
- 31-500 Series Standard Pattern, 1/2" MNPT Inlet with I.D. of NPT Thread Machined for 1/2" Copper Pipe
- (-04P) Optional Plain Finish Handle
- Made in USA

PART NUMBER	LF PART NUMBER	WT./100 (LB.)	SHANK LENGTH (IN.)	INLET (IN.)
31-202-04	31LF-202-04	43.00	5/8	3/4 MNPT
31-212-04	31LF-212-04	46.50	15/16	3/4 MNPT
31-501-04	31LF-501-04	31.00	5/8	1/2 MNPT/1/2 Sweat

31-400 SERIES COMBINATION TEE & DRAIN VALVE



Permits supplying and draining of water through a single tank tapping and meets CSA requirements.

FEATURES

- All Cast Bronze Body
- Aluminum Handwheel
- No Handle: Screwdriver Slot Stem Option
- Maximum Rated Pressure: 200 psig
- Maximum Rated Temperature: 250°F
- 3/4" FNPT inlet x 3/4" Male Hose End x 3/4" FNPT Side Outlet
- Made in USA

PART NUMBER	LF PART NUMBER	WT./100 (LB.)	HANDLE
31-401-04	31LF-401-04	62.00	Aluminum Wheel - Red
31-401-04P	31LF-401-04P	62.00	Aluminum Wheel - Plain
31-401-13	31LF-401-13	62.00	Slotted Stem