

59V Series

Mini Strainer



Job Name:	
Job Location:	
Engineer:	
Contractor:	
Tag:	
PO#:	
Rep:	
Wholesale Dist.:	

description

the Apollo 59V series "mini" strainers are designed to protect small piping systems and process equipment from unwanted foreign particles. using proven ASTM grade material the 59V offers in-line flow capabilities with easy bottom entry access for screen removal.

features

- in-Line Flow Design
- 304 stainless steel screen
- easy Maintenance
- compact design
- **made in USA**

performance rating

- 125 psig @ 350°F steam non shock
- 400 psig @ 200°F water, oil, gas, non-shock
- Cv factor
 - 1/8" = 1.03
 - 1/4" = 1.42

options

59V-00X-XX


- (0) - 1/8" FNPT
- (1) - 1/4" FNPT
- (-01) - 50 mesh (standard)
- (-C1) - 80 mesh
- (-D1) - 30 mesh
- (-H1) - 100 mesh

standard materials list

BODY	Cast Bronze, ASTM B584
CAP	Brass, ASTM B16
SCREEN	Stainless Steel, 304
O-RING	EPDM

dimensions

PART NUMBER	SIZE (IN.)	DIMENSIONS (IN.)		WT. (LB.)
		A	B	
59V-000-01	1/8	1.75	1.25	.44
59V-001-01	1/4	2.00	1.31	.42

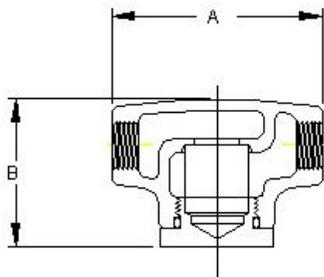

flow curves

