

# 757 BVE Series Blanking Plugs

## Increased Safety

Cable Gland Accessories.

**NEC/CEC:**  
 Class I, Groups A,B,C,D  
 Class II, Groups E,F,G  
 Class III  
 Ex e II, Class I, Zone 1  
 AEx e II; IP66, 67, 68

**ATEX/IECEx:**  
 Zone 1 and 2 – 21 and 22  
 Ⓜ II 2 GD  
 IP66

### Applications

- A comprehensive range of plastic blanking plugs designed to close any unused entries in electrical equipment.
- Entry thread sealing washer supplied.

### Features

- Catering to hazardous areas, the range covers all metric threads from M16 to M50.
- Certification Ex e.

### Standard Materials

- Nylon

### NEC/CEC Certifications and Compliances

- UL Standard: 886 (1203), E60079-0, E60079-1, E60079-7
- CSA Standard: C22.2 No. 30, CAN/CSA E60079-0, CAN/CSA E60079-1, CAN/CSA E60079-7
- cCSAus Certified: 113642

### ATEX/IECEx Certifications and Compliances


- Certification Type BVe
  - Gas: Zones 1 and 2
  - Type of Protection: Ex e II
  - Dust: Zone 21 and 22
  - Type of Protection: Ex tD
- Conforming to ATEX 94/9/CE: Ⓜ II 2GD
- Ambient Temperature: -40 °C to +55 °C (-40 °F to +131 °F)
- CE Declaration of Conformity: 5C218
- ATEX Certificate: LCIE 03 ATEX 0011U
- IECEx Certificate: IECEx LCI 04.0027U
- Index of Protection according EN/IEC 60529: IP66

### INMETRO Certification

- INMETRO Certificate: BVC 11.0600-U



Dimensions in Millimeters (Inches)

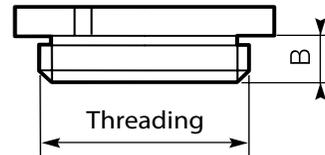

Dimensions mm (in)		Weight	Volume	Catalog Number
B	Metric	kg (lbs)	dm <sup>3</sup> (in <sup>3</sup> )	
–	M16	0.10 (0.22)	0.03 (1.83)	<b>095485</b>
12.0 (0.47)	M20	0.10 (0.22)	0.03 (1.83)	<b>095714</b>
12.0 (0.47)	M25	0.10 (0.22)	0.03 (1.83)	<b>095715</b>
12.0 (0.47)	M32	0.10 (0.22)	0.03 (1.83)	<b>095486</b>
12.0 (0.47)	M40	0.10 (0.22)	0.07 (4.27)	<b>095487</b>
–	M50	0.20 (0.44)	0.07 (4.27)	<b>095488</b>