

# Pull Boxes with Threaded Hubs and Covers

For use with Threaded Rigid Metal Conduit and IMC.

**NEC:**  
Listed for Ordinary Locations

## Applications

- Serve as pulling fittings.
- Provide openings for splicing.
- Make straight connections and 90° bends in conduit runs.
- Permit access to conductors for maintenance.

## Features

- Roomy interiors, more wiring space.
- Accurately tapped, tapered threads (NPT) for tight, rigid joints and ground continuity.

## Standard Materials

- Bodies and covers: steel
- Hubs: malleable iron or steel
- Cover bolts: trade sizes 1/2" thru 1-1/2" are zinc plated; trade sizes 2" thru 6" are brass

## Standard Finish

- Zinc electroplate, chromate and epoxy powder coat.

## NEC Certifications and Compliances

- UL Standard: 514A
- UL Listed: E2527




PTB

PTC



PTB, PTC Gasket

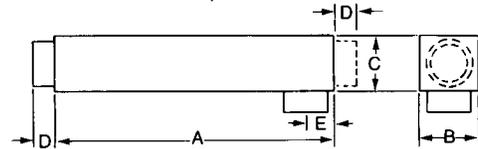

APPLETON

COMMERCIAL AND INDUSTRIAL FITTINGS; CONDUIT BODIES

| Catalog Numbers  |             | Gaskets for PTC and PTB | Hub Size (Inches) | Pull Box Dimensions (Millimeters (Inches)) |              |              |             |              |
|------------------|-------------|-------------------------|-------------------|--|--------------|--------------|-------------|--------------|
| Straight PTC Box | 90° PTB Box |                         |                   | A  | B            | C            | D           | E            |
| <b>12-inch</b>   |             |                         |                   |  |              |              |             |              |
| 1200             | 1250        | GK-12-100               | 1                 | 304.8 (12.00)                              | 55.6 (2.19)  | 54.1 (2.13)  | 21.3 (0.84) | 23.9 (0.94)  |
| 1201             | 1251        | GK-12-150               | 1-1/4             | 304.8 (12.00)                              | 63.5 (2.50)  | 62.0 (2.44)  | 26.9 (1.06) | 29.5 (1.16)  |
| 1202             | 1252        | GK-12-150               | 1-1/2             | 304.8 (12.00)                              | 63.5 (2.50)  | 62.0 (2.44)  | 26.9 (1.06) | 35.1 (1.38)  |
| 1203             | 1253        | GK-12-200               | 2                 | 304.8 (12.00)                              | 84.8 (3.34)  | 84.1 (3.31)  | 33.3 (1.31) | 42.9 (1.69)  |
| <b>18-inch</b>   |             |                         |                   |  |              |              |             |              |
| 1211             | —           | GK-18-150               | 1-1/4             | 457.2 (18.00)                              | 63.5 (2.50)  | 62.0 (2.44)  | 26.9 (1.06) | 29.5 (1.16)  |
| 1212             | —           | GK-18-150               | 1-1/2             | 457.2 (18.00)                              | 63.5 (2.50)  | 62.0 (2.44)  | 26.9 (1.06) | 35.1 (1.38)  |
| 1213             | —           | GK-18-200               | 2                 | 457.2 (18.00)                              | 84.8 (3.34)  | 84.1 (3.31)  | 33.3 (1.31) | 42.9 (1.69)  |
| 1214             | —           | GK-18-250               | 2-1/2             | 457.2 (18.00)                              | 122.2 (4.81) | 120.7 (4.75) | 40.4 (1.59) | 46.0 (1.81)  |
| <b>24-inch</b>   |             |                         |                   |  |              |              |             |              |
| 1222             | 1272        | GK-24-150               | 1-1/2             | 609.6 (24.00)                              | 63.5 (2.50)  | 62.0 (2.44)  | 26.9 (1.06) | 35.1 (1.38)  |
| 1223             | 1273        | GK-24-200               | 2                 | 609.6 (24.00)                              | 84.8 (3.34)  | 84.1 (3.31)  | 33.3 (1.31) | 42.9 (1.69)  |
| 1224             | 1274        | GK-24-300               | 2-1/2             | 609.6 (24.00)                              | 122.2 (4.81) | 120.7 (4.75) | 40.4 (1.59) | 46.0 (1.81)  |
| 1225             | 1275        | GK-24-300               | 3                 | 609.6 (24.00)                              | 122.2 (4.81) | 120.7 (4.75) | 42.2 (1.66) | 52.3 (2.06)  |
| <b>36-inch</b>   |             |                         |                   |  |              |              |             |              |
| 1244             | 1294        | GK-36-300               | 2-1/2             | 914.4 (36.00)                              | 122.2 (4.81) | 120.7 (4.75) | 40.4 (1.59) | 46.0 (1.81)  |
| 1245             | 1295        | GK-36-300               | 3                 | 914.4 (36.00)                              | 122.2 (4.81) | 120.7 (4.75) | 42.2 (1.66) | 52.3 (2.06)  |
| 1246             | 1296        | GK-36-400               | 3-1/2             | 914.4 (36.00)                              | 160.3 (6.31) | 157.2 (6.19) | 48.5 (1.91) | 60.5 (2.38)  |
| 1247             | 1297        | GK-36-400               | 4                 | 914.4 (36.00)                              | 160.3 (6.31) | 157.2 (6.19) | 48.5 (1.91) | 67.6 (2.66)  |
| <b>48-inch</b>   |             |                         |                   |  |              |              |             |              |
| 1812             | —           | GK-48-300               | 3                 | 1219.2 (48.00)                             | 122.2 (4.81) | 120.7 (4.75) | 42.2 (1.66) | 52.3 (2.06)  |
| 1813             | —           | GK-48-400               | 3-1/2             | 1219.2 (48.00)                             | 160.3 (6.31) | 157.2 (6.19) | 48.5 (1.91) | 60.5 (2.38)  |
| 1814             | —           | GK-48-400               | 4                 | 1219.2 (48.00)                             | 160.3 (6.31) | 157.2 (6.19) | 48.5 (1.91) | 67.6 (2.66)  |
| 1815             | —           | GK-48-500               | 5                 | 1219.2 (48.00)                             | 185.7 (7.31) | 182.6 (7.19) | 46.7 (1.84) | 82.6 (3.25)  |
| 1816             | —           | GK-48-600               | 6                 | 1219.2 (48.00)                             | 211.1 (8.31) | 208.0 (8.19) | 51.6 (2.03) | 102.4 (4.03) |