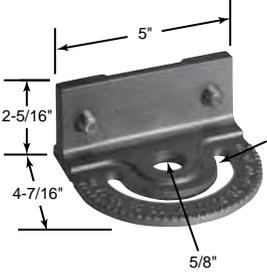
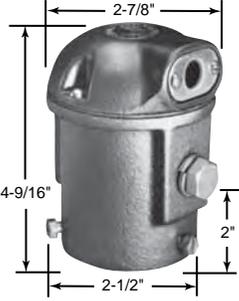
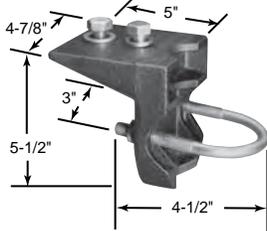
 
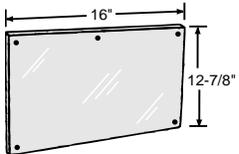


Zone 2 Areamaster™ 250/400

Accessories

Integrally ballasted floodlights for 70 W, 100 W, 150 W, 250 W and 400 W High Pressure Sodium; 175 W, 250 W and 400 W Metal Halide; and 200 W, 250 W, 320 W and 400 W Pulse Start Metal Halide. For Class I, Zone 2 AEx nR, Groups IIA, IIB, IIC locations.

Mounting Fittings and Accessories

Dimensions	Description	Catalog Number	Dimensions	Description	Catalog Number
	<p>Crossarm Mounting Bracket</p> <p>Has 180° horizontal adjustment – degree marked. Facilitates mounting floodlight to crossarm or other flat surface, or to G-AM-8-WB. Includes floodlight yoke bolts. Malleable iron, zinc plated, chromate sealed, architectural bronze POLYESTER finish.</p>	G-AM-8-CA		<p>Poletop Slip-Fitter</p> <p>Slip-fits 1-1/2" or 2" pipe size poletop tenons. Includes floodlight yoke bolts, 3 locking bolts, and cord grip. Body is malleable iron, zinc plated, chromate sealed, with cast aluminum cap. Assembly has architectural bronze POLYESTER finish.</p>	G-SF20
	<p>Pipe or Wall Mount Bracket</p> <p>Used with G-AM-8-CA. Clamps to 1" to 2-1/2" pipe, vertical or horizontal, or mounts on flat surfaces. Includes U-bolt and crossarm bracket bolts. Malleable iron, zinc plated, chromate sealed, with architectural bronze POLYESTER finish.</p>	G-AM-8-WB		<p>Top Visor</p> <p>Easy to install with hardware supplied. Aluminum, with architectural bronze POLYESTER finish.</p>	G-AM-6-V
	<p>Vandal Shield</p> <p>UV stabilized polycarbonate, with installation hardware and instructions.</p>	G-AM-6-VS		<p>Replacement Lens</p>	604249003