

WYT/YT Type Checkered Cover Sidewalk Boxes

Weatherproof

Cast Iron Box for Flush Mounting.

NEC/CEC:

Rated for Ordinary (Unclassified) Locations

Applications

- These boxes are specially designed to be mounted in sidewalks and other flat concrete surfaces. Their checkered covers are made to withstand pedestrian traffic.
- The flanges and covers are interchangeable to permit replacement without disturbing the box or conduit system.
- Heavy checkered steel covers can be furnished which will accommodate vehicular traffic (see *Options*).

Features

- Type WYT boxes have a post in each corner and allowances must be made for them, when conduit entrances are to be located close to a corner.
- Cross ribbed, heavy duty cover with pry bar slots.
- Checkered cover provides non-slip surface.
- Neoprene gasket – between cover and box.
- Wide selection of locations for drilled and tapped and slip hole conduit entrances.

Standard Materials


- Box and cover: cast iron
- Gasket: neoprene
- Screws: stainless steel

Standard Finishes

- Box and cover: hot dip galvanized

Options

- Checkered steel covers suitable for vehicular traffic H-25 loading, add suffix **-CSV**.
- Engraved lettering on cover per specifications.
- For additional options see *Ordering Information* pages.

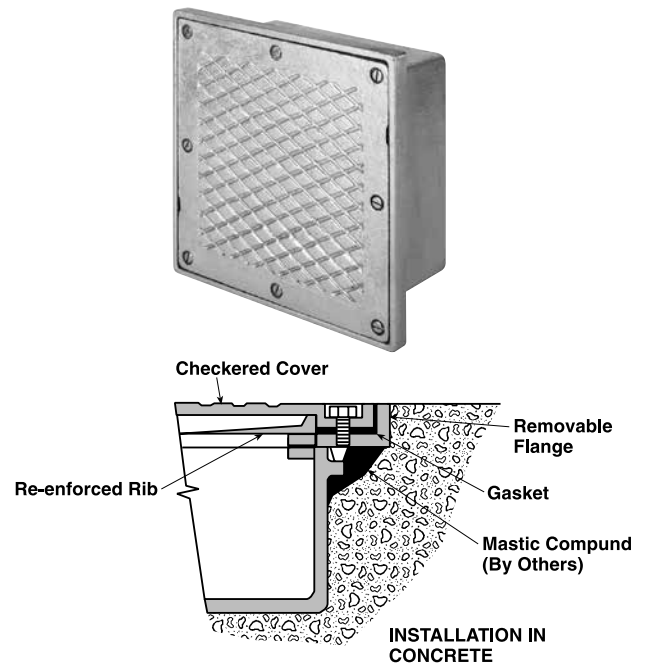

Inside Dimensions mm (in)					Approximate Wall Thickness ① mm (in)	Appleton Catalog Number	O-Z/Gedney Catalog Number
L	x	W	x	D			
152.4 (6.00)	x	152.4 (6.00)	x	101.6 (4.00)	7.94 (0.3125)	WYT-060604	YT-060604
203.2 (8.00)	x	152.4 (6.00)	x	101.6 (4.00)	7.94 (0.3125)	WYT-080604	YT-080604
203.2 (8.00)	x	203.2 (8.00)	x	152.4 (6.00)	7.94 (0.3125)	WYT-080806	YT-080806
304.8 (12.00)	x	203.2 (8.00)	x	203.2 (8.00)	7.94 (0.3125)	WYT-120808	YT-120808
304.8 (12.00)	x	304.8 (12.00)	x	152.4 (6.00)	7.94 (0.3125)	WYT-121206	YT-121206
609.6 (24.00)	x	304.8 (12.00)	x	203.2 (8.00)	7.94 (0.3125)	WYT-241208	YT-241208

① Measured 50.8 mm (2.00") up from back of box.