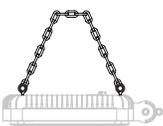


Areamaster™ LED Flood/High Bay Luminaires

For Hazardous Locations. 250 W, 400 W, 750 W, 1000 W HID Light Level Equivalent

LIGHTING/LED/FLOODLIGHTS: NEC/CEC, ATEX/IECEx ENCLOSED AND GASKETED

Accessories and Replacement Parts

Description		Catalog Number NEC/CEC, ATEX/IEC
Crossarm Mounting Bracket		
	Has 180° horizontal adjustment — degree marked. Facilitates mounting floodlight to crossarm or other flat surface, or to G-AM-8-WB. Includes floodlight yoke bolts. Malleable iron, zinc plated, chromate sealed, architectural bronze polyester finish.	G-AM-8-CA
Pipe or Wall Mount Bracket		
	Used with G-AM-8-CA. Clamps to 1" to 2-1/2" pipe, vertical or horizontal, or mounts on flat surfaces. Includes U-bolt and crossarm bracket bolts. Malleable iron, zinc plated, chromate sealed, with architectural bronze polyester finish.	G-AM-8-WB
Poletop Slip-Fitter		
	Slip-fits 1-1/2" or 2" pipe size poletop tenons. Includes floodlight yoke bolts, 3 locking bolts, and cord grip. Body is malleable iron-zinc plated, chromate sealed, with cast aluminum cap. Assembly has architectural bronze polyester finish.	G-SF20
	Slip-fits 1" or 1-1/2" pipe size poletop tenons. Includes floodlight yoke bolts, 3 locking bolts, and cord grip. Body is malleable iron-zinc plated, chromate sealed, with cast aluminum cap. Assembly has architectural bronze polyester finish.	AMLEDSF1
Poletop Slip-Fitter		
	Slip-fits 2" or 2-1/2" poletop tenons. Includes floodlight yoke bolts, 3 locking bolts, and cord grip. Malleable iron, zinc plated, chromate sealed, with architectural bronze polyester finish.	G-AM-8-SF
Chain		
	Chain mount assembly comes with two (2) 914.4 mm (36 inch) long chains, four (4) eye bolts, four (4) hex bolts, four (4) lock washers, four (4) hex nuts, eight (8) plain washers and an instruction sheet for complete assembly and mounting. Chains are galvanized steel, eye bolts are zinc plated steel, all other hardware is stainless steel.	AMLEDCM

Description	NEC/CEC	Catalog Number ATEX/IECEx
LED Array		
With White LED's for the AMLED67	AMLED67AW	AMLED67AW
With White LED's for the AMLED77	AMLED77AW	AMLED77AW
With White LED's for the AMLED87	AMLED87AW	AMLED87AW
Drivers		
120 - 277 Vac — BU Version and BC Version	AMLED77DBU	—
120 - 277 Vac — BU1 Version — AMLED87: Left Side — AMLED67, AMLED77	AMLEDDBU1L	AMLEDDBU1L
120 - 277 Vac — BU1 Version — AMLED87: Right Side	AMLEDDBU1R	AMLEDDBU1R
347 - 480 Vac — BH Version — AMLED67, AMLED77	AMLED77DBH	—
347 - 480 Vac — BH Version — AMLED87: Left Side	AMLED87DBHL	—
347 - 480 Vac — BH Version — AMLED87: Right Side	AMLED87DBHR	—
Door Assembly		
With a Glass Lens, Pins	AMLEDMDOOR	AMLEDMDOOR
With a Polycarbonate Lens, Pins	AMLEDMDOORP	—