

CPS Factory Sealed 20 Amp Pin and Sleeve Receptacles

Explosionproof

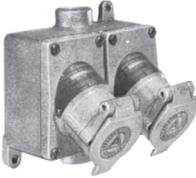
120-240 Vac, 20 Amp at 1 HP; 20 Amp at 24 Vdc. Dead-Front Safety Construction.

NEC/CEC ②:
 Class I, Division 1 and 2 Groups B♦, C, D
 Class II, Division 1 and 2 Groups F, G
 NEMA 3RX*, 7BCD

Does not intermate with
 Contender™ CPS 20 Amp
 Pin and Sleeve Receptacles

APPLETON

PLUGS AND RECEPTACLES: NEC/CEC HAZARDOUS LOCATION

	Type	Number of Gangs	Wire/Pole	Hub Size (Inches)	Catalog Number
CPS Receptacle 15° Angle Type					
	Dead-End	—	2W, 3P	1/2 3/4	CPSA-2350 CPSA-2375
					
CPS Receptacles with EFD Mounting Boxes					
 CPC1	Dead-End	Single	2W, 3P	1/2 3/4 1	CPE1-2350 CPE1-2375 CPE1-23100
	Feed-Thru	Single	2W, 3P	1/2 3/4 1	CPC1-2350 CPC1-2375 CPC1-23100
 CPC2 ①	Dead-End	Two	2W, 3P	1/2 3/4 1	CPE2-2350 CPE2-2375 CPE2-23100
	Feed-Thru	Two	2W, 3P	1/2 3/4 1	CPC2-2350 CPC2-23100 CPC2-2375
CPS Replacement Receptacle and Cover Assembly					
	CPSR		2W, 3P		CPSR-23
	Replacement Spring Cover				CPSCA
CPR Replacement Receptacle Cover Assembly Only					
	CPR		2W, 3P		CPR23
	Spring Cover Kit				CPRCA
	NEMA 3X Corrosion Resistance Kit •				CPS233RXKIT
	Description		Wire/Pole	Cable Dia. (Inches)	Catalog Number
CPP Plugs for use with CPS Receptacles					
	Pressure Terminals				
	Plug amperes match receptacle ratings		2W, 3P	.536 to .639	CPP2023

• NEMA 3X with Screw Cover Kit installed and cover full engaged.

① Suitable for Class I, Group C, D; Class I, Division 2, Group B, C, D; Class II, Groups F, G.

② For CEC version with CSA nameplate, add suffix **-CN** to plug and receptacle catalog number.

♦ Shaded area indicates items suitable for Class I, Group B in addition to Class I, Groups C and D. Applies to UL only.