

U-Line™ Factory Sealed 20 Amp Panel Mounting Receptacles

Explosionproof, Dust-Ignitionproof, Watertight

125 Vac, 20 Amp, 1 HP; 250 Vac, 20 Amp, 2HP. Dead-Front Safety Construction.

NEC/CEC ③:

Class I, Division 1 and 2, Groups B, C, D

Class II, Division 1 and 2, Groups F, G


Class III

NEMA 3, 3R, 3RX*, 4X*, 7BCD, 9F①G

20 Amp Aluminum Panel Mounting Receptacles

	Thread Size and Type ②	Wire/Pole	NEC Catalog Number		CEC Catalog Number	
			125 Vac, 1 HP	250 Vac, 2 HP	125 Vac, 1 HP	250 Vac, 2 HP
	1-1/2" (1-1/2—11-1/2 NPT)	2W, 3P	ECHT2023	ECHT20232	ECHT2023CN	ECHT20232CN
	2" (2—11-1/2 NPSM)	2W, 3P	ECH2023	ECH20232	ECH2023CN	ECH20232CN

Dimensions in Millimeters (Inches)

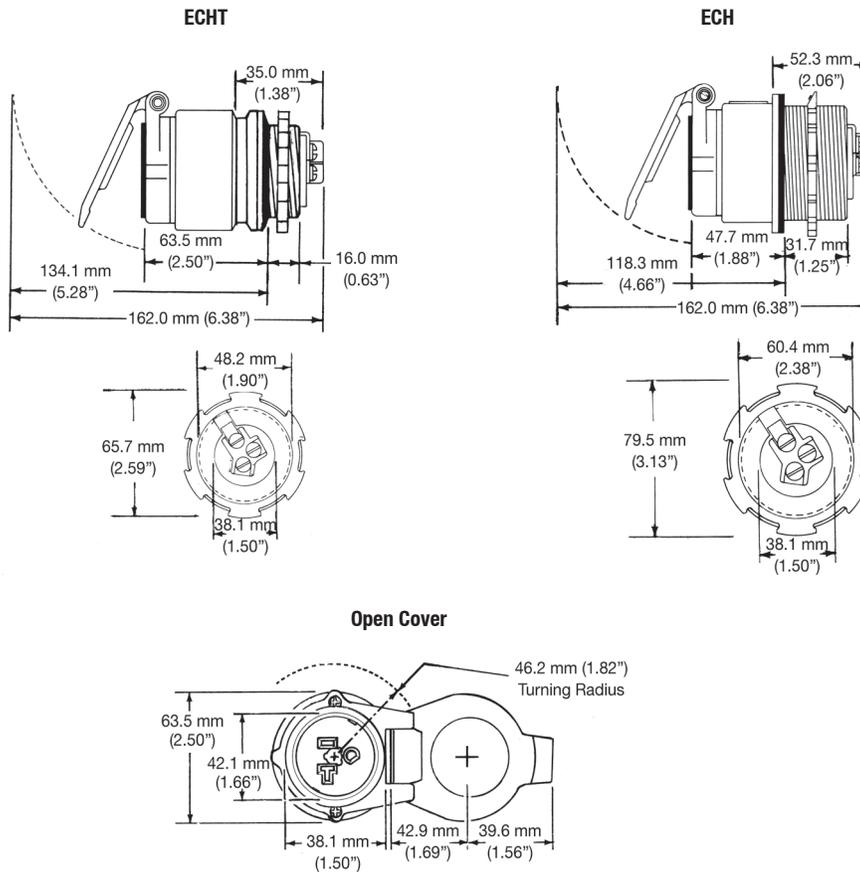

① Do not use where electrically conductive dusts are present (most coal dusts are not electrically conductive).

② ECHT has 1-1/2" tapered threads (1-1/2-11-1/2 NPT); ECH has 2" straight threads (2—11-1/2 NPSM).

③ For CEC version with CSA nameplate, add suffix **-CN** to catalog number.

▼ NEMA 3RX when the spring-loaded cover is installed and closed on a suitable enclosure. NEMA 4X when the screw cover is installed on a suitable enclosure and fully engaged.