

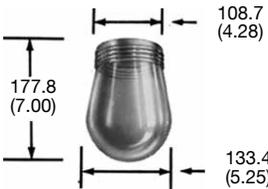
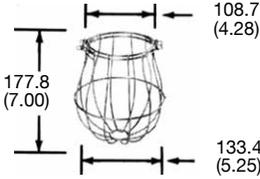
# EDT Incandescent Luminaires

## Dust-Ignitionproof

Suitable for use in Wet Locations.

NEC/CEC:

Class II, Division 1 and 2, Groups E, F, G  
Class III

Description	Watts	Hub Size (Inches)	Catalog Number
<b>Pendant Lighting Fixture mm (in)</b> <sup>①</sup> 	60-200 W	1/2	<b>EDTP2050</b>
<b>Heat-Resistant Clear Glass Globe</b> 	60-200 W		<b>VSGL-2HR</b>
<b>Globe Guard</b> 	60-200 W		<b>DPGU-2</b>
<b>Replacement Porcelain Shock-Absorbing Socket – Medium Base</b> 	60-200 W		<b>VPLR-123</b>

<sup>①</sup> T3C maximum operating temperature. Supply wire +150 °C (+302 °F). Maximum ambient temperature +25 °C (+77 °F). Vertical mount only (globe down).