

FS and FD Cast Hub Device Boxes

UNILETS™ for use with Threaded Rigid Metal Conduit and IMC. Furnished with Internal Ground Screw.

NEC:
Listed for Ordinary Locations

FS Box (Shallow) 2.00" deep, FD Box (Deep) 2.69" deep, ED (Extra Deep) 3.06" deep

| | Type | Depth | Hub Size (Inches) | Catalog Number | |
|---|------|----------------|-------------------|--------------------------|--------------------|
| | | | | Malleable Iron Ridge Top | Aluminum Ridge Top |
|  | FS | Shallow | 1/2 | FS-2-50 | FS-2-50-A |
| | | | 3/4 | FS-2-75 | FS-2-75-A |
| | | | 1 | FS-2-100 | — |
| | FD | Deep | 1/2 | FD-2-50 | — |
| | | | 1/2 | FD-2-50ED | — |
| | | | 3/4 | FD-2-75 | FD-2-75-A |
| | | | 3/4 | FD-2-75ED | — |
|  | FSC | Shallow | 1/2 | FSC-2-50 | — |
| | | | 3/4 | FSC-2-75 | FSC-2-75-A |
| | | | 1 | FSC-2-100 | — |
| | FDC | Deep | 1/2 | FDC-2-50 | — |
| | | | 1/2 | FDC-2-50ED | — |
| | | | 3/4 | FDC-2-75 | FDC-2-75-A |
| | | | 3/4 | FDC-2-75ED | — |
| | | | 1 | FDC-2-100 | — |
| | | | 1 | FDC-2-100ED | — |
|  | FSS | Shallow | 1/2 | FSS-2-50 | — |
| | | | 3/4 | FSS-2-75 | FSS-2-75-A |
| | | | 1 | FSS-2-100 | — |
|  | FDS | Deep | 3/4 | FDS-2-75 | — |
| | | | | | |
|  | FSD | Shallow ① | 1/2-3/4 | FSD-2-75 | — |
| | | | | | |
|  | FS | 1" Extension ② | — | FS-2EXT | — |
| | | | | | |

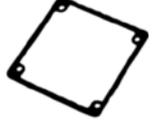
① Largest hub at bottom in illustration.

② Extension does not have a ground screw.

Shaded boxes include mounting feet (feet not shown for boxes on this page).

FS and FD Cast Hub Device Boxes

NEC:
Listed for Ordinary Locations

| | Description | Catalog Number | |
|---|---|-----------------------|------------------|
| | | Steel | Aluminum |
| Stamped Steel and Aluminum Covers – With stainless steel screws, less gasket | | | |
|  | For square handle tumbler or toggle flush switches | FSK-2TS | FSK-2TS-A |
|  | For two round receptacles. Mounts on device. Hole Dia. – 1-13/32" | FSK-2R-Q | — |
| | For two round receptacles. Mounts directly on box. Hole Dia. – 1-13/32" | FSK-2R-W | — |
|  | For round flush receptacles, with lift cover. Mounts on device. Hole Dia. – 1-13/32" | FSK-2R-T | — |
|  | For duplex flush receptacles | FSK-2DR | FSK-2DR-A |
|  | For tumbler flush switch and duplex flush receptacles | FSK-2RS-K | — |
|  | For round flush receptacle and duplex receptacles Hole Dia. – 1-13/32" | FSK-2R-L | — |
|  | For round receptacles. Hole Dia. – 2-15/32 | FSK-2R-M | — |
|  | Blank Cover | FSK-2B | FSK-2B-A |
| | | Malleable Iron | Aluminum |
| Cast Covers – Weatherproof – With gasket and stainless steel screws | | | |
|  | Blank Cover | FSK-2B-CM | FSK-2B-CA |
|  | Gasket – Replacement | | |
| | Neoprene – for use with 2-gang cast covers above | FS-GKR-2N | — |

COMMERCIAL AND INDUSTRIAL FITTINGS: CAST DEVICE BOXES

APPLETON™