

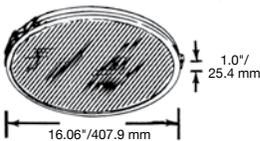
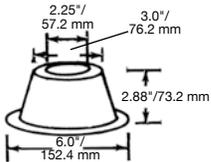
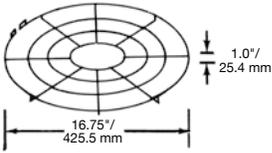
Baymaster 250/400™ High Bay Luminaire Accessories and Replacement Parts

150 W, 250 W, 400 W HPS; 175 W, 200 W, 250 W, 320 W, 400 W, 450 W PSMH; 175 W, 250 W, 400 W MH ; 300 W-500 W Incandescent.

For Incandescent Lamps or HID lamps and Remote Ballast

Lamp Type	Voltage	Catalog Number
For Incandescent Lamps or HID lamps and Remote Ballast 		
300 W-500 W PS-35, incandescent		G-H71AM-RB
250 W-400 W, HPS		G-H71AL-RB
250 W, PSMH/MH		G-H71AM-RB
400 W, PSMH/MH		G-H71AM-RB

Accessories and Replacement Parts

Type	Description	Catalog Number
Glass Lenses 		
	With clear, thermal shock and impact resistant glass lens.	G-HB7000-NL
	With prismatic Corning-73 thermal shock and impact resistant lens.	G-HB7000-NL3
Reflector		
	Reflector only.	G-7AW
Socket Shroud		
	Aluminum, with gasket (closes off reflector).	G-HB7000-SS
Wire Guard		
	Has relamp opening, zinc plated.	G-HB7000-NG
Safety Cable (not shown)		
		G-HB7000-SC
Fuseholder		
	Has 9\" data-bbox="338 755 508 765"/> wire leads.	G-F10
Wiring Kit (not shown)		
	Supplied with 3 feet of 16/3 SOOW cable and FHHM-75SS cast safety hook	PWK 

 For remote ballast consult your local sales representative.

 Lens assemblies shown have stainless steel frame and are furnished with an aluminum socket shroud to close off reflector top (shroud shown). Can be field installed.

 CSA Certification only.

LIGHTING: GENERAL LIGHTING – AREA – HIGH BAY

Lighting