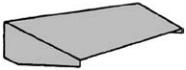


# Areamaster™ 1000 Floodlights

## Integrally Ballasted. 1000 W and 1500 W HID

For ordinary locations. NOT available for use in CEC governed locations.

**NEC:**  
Listed for Ordinary (Unclassified) Locations

	Description	Catalog Numbers
<b>Crossarm Mounting Bracket</b> 	Has 180° horizontal adjustment — degree marked. Facilitates mounting floodlight to crossarm or other flat surface, or to G-AM-8-WB. Includes floodlight yoke bolts. Malleable iron, zinc plated, chromate sealed, architectural bronze polyester finish.	<b>G-AM-8-CA</b>
<b>Pipe or Wall Mount Bracket</b> 	Used with G-AM-8-CA. Clamps to 1" to 2-1/2" pipe, vertical or horizontal, or mounts on flat surfaces. Includes U-bolt and crossarm bracket bolts. Malleable iron, zinc plated, chromate sealed, with architectural bronze polyester finish.	<b>G-AM-8-WB</b>
<b>Poletop Slip-Fitter</b> 	Slip-fits 1-1/2" or 2" pipe size poletop tenons. Includes floodlight yoke bolts, 3 locking bolts, and cord grip. Body is malleable iron-zinc plated, chromate sealed, with cast aluminum cap. Assembly has architectural bronze polyester finish.	<b>G-SF20</b>
	Slip-fits 2" or 2-1/2" poletop tenons. Includes floodlight yoke bolts, 3 locking bolts, and cord grip. Malleable iron, zinc plated, chromate sealed, with architectural bronze polyester finish.	<b>G-AM-8-SF</b>
<b>Locking-Type Photocontrol Receptacle</b> 	For NEMA type photocontrol, with installation hardware and instructions.	<b>G-1PCR</b>
<b>Vandal Shield</b> 	UV stabilized polycarbonate, with installation hardware and instructions.	<b>G-AM-8-NVS</b>
<b>Top Visor</b> 	Easy to install with hardware supplied. Aluminum, with architectural bronze polyester finish.	<b>G-AM-6-NV</b>

HID/FLOODLIGHT: NEC/CEC ORDINARY LOCATION

Appleton®