

Super-Baymaster™ High Bay Luminaires

High Bay Luminaires for Mill Duty and Corrosive Atmospheres


150 W, 175 W, 250 W, 400 W or 1000 W HPS; 1000 W PSMH; 1000 W MH.

CEC:

Listed for Ordinary (Unclassified) Locations

Order using catalog numbering guide below or select catalog number from tables on following pages.

Catalog Numbering Guide for GSB and GSS

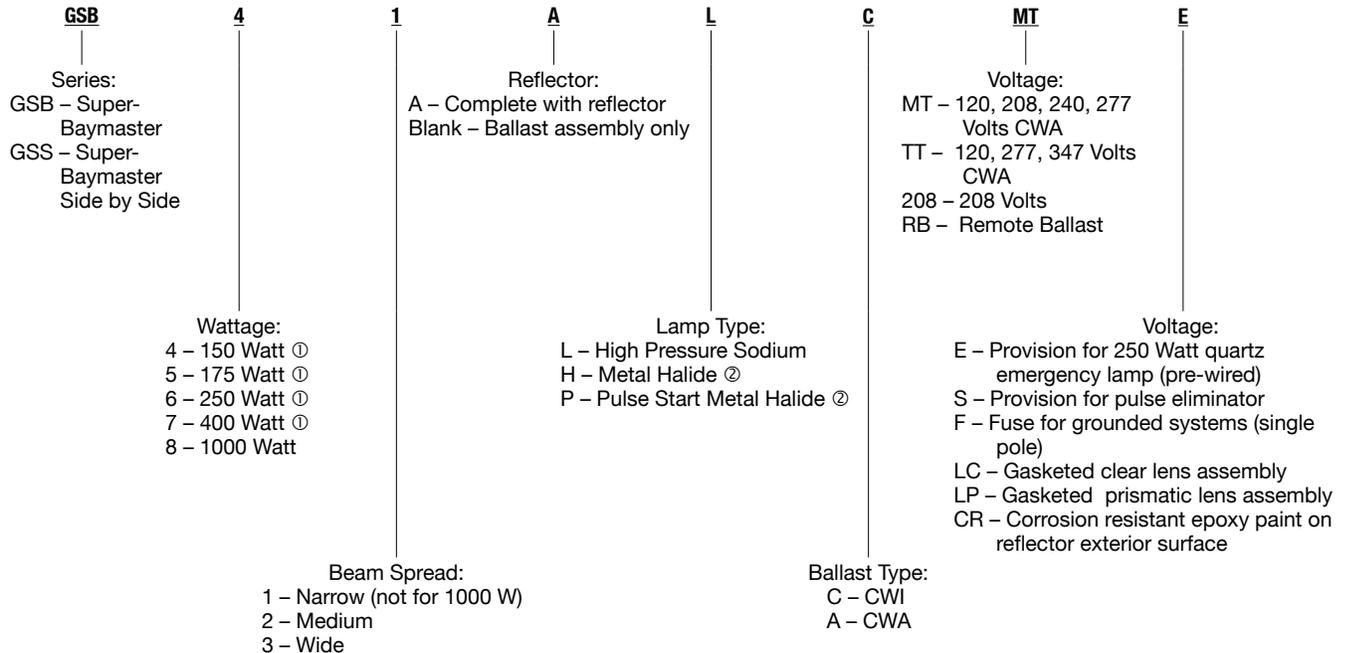

Accessories and Replacement Parts

	Description	Catalog Number
Wire Guard	With relamp door. Zinc plated	G-HB20-G
Safety Chain	Secures ballast and reflector	G-HB-7000-SC
Wiring Kit	Supplied with 0.91 meters (3 feet) of 600 Volt +90 °C (+194 °F) 3-conductor no. 16 SOW cable and 19.1 mm (3/4") FHHM hook (shipped separately) Add Suffix:	PWK
Sockets	Socket for Metal Halide	SPF-1004
	Socket for High Pressure Sodium	SPF-1001

① Only available in high pressure sodium.

② Only available in 1000 Watt.