

# Baymaster™ Prismatic 250/400 High Bay Luminaires

150 W, 250 W, 400 W HPS.

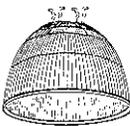
**NEC/CEC:**

Listed for Ordinary (Unclassified) Locations

## High Pressure Sodium Lamps — Pendant Mounting

Lamp Wattage	Voltage	Catalog Number	
		Complete Assembly ①	Ballast Housing Assembly
150 W	120/208/240/277 V	G-HB41PL-MT	G-HB411L-MT
	120/277/347 V	G-HB41PL-TT ③②	G-HB411L-TT ③②
	480	G-HB41PL-48	G-HB411L-48
250 W	120/208/240/277 V	G-HB61PL-MT	G-HB611L-MT
	120/277/347 V	G-HB61PL-TT ③②	G-HB611L-TT ③②
	480	G-HB61PL-48	G-HB611L-48
400 W	120/208/240/277 V	G-HB71PL-MT	G-HB711L-MT
	120/277/347 V	G-HB71PL-TT ③②	G-HB711L-TT ③②
	480	G-HB71PL-48	G-HB711L-48

## Accessories

	Description	Catalog Number
	16" Prismatic Reflector only.	G-7PR
	16" Prismatic Reflector with clamp band and clear tempered glass lens.	G-7PR-IL ③
	16" Prismatic Reflector with clamp band and prismatic acrylic lens.	G-7PR-ILP ③

① To order fixture complete with lamp, add suffix **-L** to catalog number.

Add suffix **-E** to catalog number if provision for 150 W quartz emergency lamp is desired (lamp not included). Furnished with socket installed and pre-wired.

② Supplied complete with CWA Ballast. For 208, 240, 480 or 600 V CWI applications, change the **-TT** suffix to **-C2**, **-C3**, **-C6** or **-C7** as required.

③ Certified to meet the Canadian Electrical Code (CEC) only.