


Set Screw Insulated Grounding Bushings for Threadless Rigid Metal Conduit and IMC

GIB-LS-AC Series — with Aluminum Lay-In-Lug™ for Copper or Aluminum Conductors.
GIB-LS-BC Series — with Bronze Lay-In-Lug™ for Copper Conductors Only.

CF

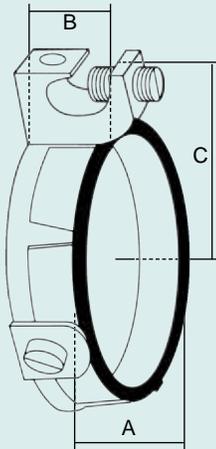

Catalog No. Aluminum Lug	Catalog No. Bronze Lug	Wire Size Size (In.)	Min.	Max.	Dimensions in Inches		
					A Bushing Dia.	B Bushing Height	C Turning Radius w/Lug
Insulated – 150°C Temperature Rating– Malleable Iron, Zinc Electroplated							
GIB-50LS-4AC	GIB-50LS-4BC	1/2	14 SOL	4 STR	1-3/16	7/16	1-3/16
GIB-75LS-4AC	GIB-75LS-4BC	3/4	14 SOL	4 STR	1-7/16	1/2	1-5/16
GIB-100LS-4AC	GIB-100LS-4BC	1	14 SOL	4 STR	1-3/4	9/16	1-7/16
GIB-100LS-20AC	GIB-100LS-20BC	1	14 SOL	2/0 STR	1-3/4	9/16	1-11/16
GIB-125LS-4AC	GIB-125LS-4BC	1-1/4	14 SOL	4 STR	2-1/8	5/8	1-5/8
GIB-125LS-20AC	GIB-125LS-20BC	1-1/4	14 SOL	2/0 STR	2-1/8	5/8	1-13/32
GIB-150LS-4AC	GIB-150LS-4BC	1-1/2	14 SOL	4 STR	2-5/16	11/16	1-3/4
GIB-150LS-20AC	GIB-150LS-20BC	1-1/2	14 SOL	2/0 STR	2-5/16	11/16	2
GIB-200LS-4AC	GIB-200LS-4BC	2	14 SOL	4 STR	2-13/16	3/4	2
GIB-200LS-20AC	GIB-200LS-20BC	2	14 SOL	2/0 STR	2-13/16	3/4	2-1/4
GIB-250LS-4AC	GIB-250LS-4BC	2-1/2	14 SOL	4 STR	3-3/8	7/8	2-1/4
GIB-250LS-20AC	GIB-250LS-20BC	2-1/2	14 SOL	2/0 STR	3-3/8	7/8	2-1/2
GIB-250LS-25AC	GIB-250LS-25BC	2-1/2	6 STR	250 STR	3-3/8	7/8	2-15/32
GIB-300LS-4AC	GIB-300LS-4BC	3	14 SOL	4 STR	4-1/16	1-5/16	2-5/8
GIB-300LS-20AC	GIB-300LS-20BC	3	14 SOL	2/0 STR	4-1/16	1-5/16	2-13/16
GIB-300LS-25AC	GIB-300LS-25BC	3	6 STR	250 STR	4-1/16	1-5/16	3-5/16
GIB-350LS-4AC	GIB-350LS-4BC	3-1/2	14 SOL	4 STR	4-1/2	1	2-7/8
GIB-350LS-20AC	GIB-350LS-20BC	3-1/2	14 SOL	2/0 STR	4-1/2	1	3-1/16
GIB-350LS-25AC	GIB-350LS-25BC	3-1/2	6 STR	250 STR	4-1/2	1	3-1/2
GIB-400LS-4AC	GIB-400LS-4BC	4	14 SOL	4 STR	5-3/16	1-1/16	3-1/8
GIB-400LS-20AC	GIB-400LS-20BC	4	14 SOL	2/0 STR	5-3/16	1-1/16	3-3/8
GIB-400LS-25AC	GIB-400LS-25BC	4	6 STR	250 STR	5-3/16	1-1/16	3-13/16
GIB-500LS-4AC	GIB-500LS-4BC	5	14 SOL	4 STR	6-1/16	1-1/4	3-5/8
GIB-500LS-20AC	GIB-500LS-20BC	5	14 SOL	2/0 STR	6-1/16	1-1/4	3-7/8
GIB-500LS-25AC	GIB-500LS-25BC	5	6 STR	250 STR	6-1/16	1-1/4	4-5/16
GIB-600LS-4AC	GIB-600LS-4BC	6	14 SOL	4 STR	7-1/4	1-5/16	4-1/4
GIB-600LS-20AC	GIB-600LS-20BC	6	14 SOL	2/0 STR	7-1/4	1-5/16	4-7/16
GIB-600LS-25AC	GIB-600LS-25BC	6	6 STR	250 STR	7-1/4	1-5/16	4-7/8