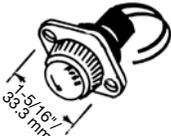
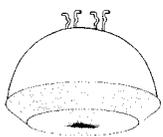


Lumenmaster 400™ Low Bay HID Prismatic Luminaires

Integrally Ballasted. 400 W, 250 W HPS; 320 W, 400 W PSMH. 400 W MH 

Suitable for use in damp locations

Pendant Mounting		Catalog Number	
Lamp Type	Voltage	Complete with Reflector/Refractor Assembly and Ballast ①②	Ballast Housing Assembly
For High Pressure Sodium Lamps			
250 W HPS	120/208/240/277 V	G-LM61BL-MT	G-LM611L-MT
250 W HPS	120/277/347 V	G-LM61BL-TT  ④	G-LM611L-TT  ④
250 W HPS	480 V	G-LM61BL-48	G-LM611L-48
400 W HPS	120/208/240/277 V	G-LM71BL-MT	G-LM711L-MT
400 W HPS	120/277/347 V	G-LM71BL-TT  ④	G-LM711L-TT  ④
400 W HPS	480 V	G-LM71BL-48	G-LM711L-48
For Pulse Start Metal Halide Lamps			
320 W PSMH	120/208/240/277 V	G-LM321BP-MT	G-LM3211P-MT
320 W PSMH	120/277/347 V	G-LM321BP-TT  ④	G-LM3211P-TT  ④
320 W PSMH	480 V	G-LM321BP-48	G-LM3211P-48
400 W PSMH	120/208/240/277 V	G-LM71BP-TT  ④	G-LM711P-MT
400 W PSMH	120/277/347 V	G-LM71BP-MT	G-LM711P-TT  ④
400 W PSMH	480 V	G-LM71BP-48	G-LM711P-48
For Metal Halide Lamps 			
400 W MH	120/208/240/277 V	G-LM71BH-MT 	G-LM711H-MT 
400 W MH	120/277/347 V	G-LM71BH-TT  ④	G-LM711H-TT  ④
Accessories and Replacement Parts ③			
Type	Description	Catalog Number	
Fuseholder with 9" wire leads			
	Zinc plated.	G-F10	
Safety Cable (not shown)		G-HB7000-SC	
Optic Assembly			
	Optic Assembly only.	G-LM30	
Wiring Kit (not shown)		Supplied with 3 feet of 16/3 SOOW cable and FHHM-75SS cast safety hook	PWK 

① To order fixture complete with lamp, add suffix **-L** to catalog number.

② Add Suffix **-E** to catalog number if provision for quartz emergency lamp is desired (lamp not included). Furnished with socket installed and pre-wired.

③ For power hook, fusing and other suspension accessories, see Fixture Hanger Accessories.

④ Supplied complete with CWA Ballast. For 208, 240, 480 or 600 V CWI applications, change the **-TT** suffix to **-C2**, **-C3**, **-C6** or **-C7** as required. 

 CSA Certification only.