

GRJS Universal Conduit Outlet Boxes

Explosionproof, Dust-Ignitionproof, Weather Resistant (Raintight)

UNILETS™ for use with Threaded Metal Conduit.

CEC:

Class I, Division 1 and 2, Groups C, D
Class I, Zone 1 and 2, IIB T6
Class II, Division 1 and 2, Groups E, F, G
Class III, Enclosure 3

Applications

- Complies with a wide range of classified area requirements.
- Corrosion-resistant: ideal indoors or out.
- For pulling of wires.
- Connect conduit lengths and change direction of conduit runs.
- Provide access for maintenance.

Features

- Malleable iron bodies have high tensile strength and ductility. Provides great resistance to corrosion, impact, and shock.
- Accurately tapped, tapered hub threads for tight, rigid joints and ground continuity.
- Furnished with covers.
- General purpose wiring.
- Universal design with five threaded openings and three close-up plugs.
- Compact round box for use where space is limited.
- Serve as mounting means for lighting fixtures when used with hub cover.
- Function as sealing fittings when used with sealing covers (see CEC for restrictions).
- Internally threaded body with externally threaded cover.
- Smooth, rounded integral bushing in each hub type box protects conductor insulation.

Standard Materials

- Bodies: malleable iron or copperfree (4/10 of 1% max.) aluminum
- Covers: copperfree (4/10 of 1% max.) aluminum

Standard Finishes

- Bodies: triple-coat — (1) zinc electroplate, (2) chromate, and (3) epoxy powder coat
- Covers: epoxy powder coat

CEC Certifications and Compliances

- CSA Standard: C22.2 No. 25, C22.2 No. 30
- CSA Certified: 013017

	Conduit Size (Inches)	Catalog Number	
		Malleable Iron	Aluminum

GRJS Universal Box with Cover

The Unilet has five threaded hubs, one in each of four sides and one in bottom. Three close-up plugs are furnished. Unilet opening is 2-9/16". Furnished with externally threaded blank surface cover and three close-up plugs. Supplied with O-ring.




1/2	GRJS50-CN	GRJS50-A
3/4	GRJS75-CN	GRJS75-A
1	GRJS100-CN	GRJS100-A

GRJS Aluminum Covers

Furnished with internal threads.

	Surface Cover	GRJSKCN
	Sealing Cover	GRJSK-SCCN
	1/2" Hub Cover	GRJSK50-CN

Dimensions in Millimeters (Inches)

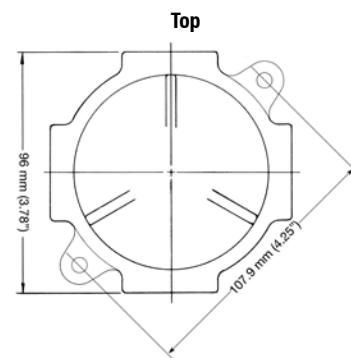

Side

