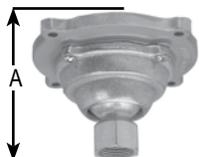


JB and GS Flexible Fixture Hangers

Ball Type, 15° Swing; Cushion Type, 8° Swing
 UNILETS™ for Use with Threaded Rigid Metal Conduit and IMC.

NEC/CEC: Listed for Ordinary (Unclassified) Locations

	Support Weight in kg (lbs)	Fixture Stem Size (Inches)	Length A mm (in)	Weight in kg (lbs)	Catalog Number Malleable Iron
JB—Fixture Hanger Covers — For use with JBX, JBDX and JBLX bodies — Furnished with gasket and screws					
 <p>Ball Type</p>	113 (250)	1/2	65.0 (2.56)	0.62 (1.37)	JBK-50-BS
		3/4	65.0 (2.56)	0.55 (1.22)	JBK-75-BS
 <p>Cushion Type — Enclosed and gasketed. Cushions 18.0 kg. (40 lbs.)</p>	18 (40)	1/2	41.4 (1.63)	0.77 (1.70)	JBK-50-CS
		3/4	41.4 (1.63)	0.67 (1.47)	JBK-75-CS
Conduit Size (Inches)	Depth in Millimeters (Inches) (A)	Weight in kg (lbs)	Catalog Number Malleable Iron	Weight in kg (lbs)	Catalog Number Aluminum
Cast Covers — Furnished with screws — When used with gasket provides raintight fit, supports 113.4 kg (250 lb)					
	1/2	20.0 (0.75)	0.44 (0.97)	JBK-50	JBK-50-A
	3/4	23.9 (0.94)	0.49 (1.09)	JBK-75	JBK-75-A
Gasket — Neoprene					
	—	—	0.01 (0.20)	JB-GK-N	JB-GK-N
	Support Weight in kg (lbs)	Fixture Stem Size (Inches)	Length A mm (in)	Weight in kg (lbs)	Catalog Number Malleable Iron
GS—Fixture Hanger Covers (Form 20) — For use with GS and GSU bodies — Furnished with gasket and screws					
 <p>Ball Type</p>	113.0 (250.00)	1/2	76.2 (3.00)	0.89 (1.97)	GSK-50-20B
		3/4	82.6 (3.25)	0.89 (1.96)	GSK-75-20B
 <p>Cushion Type — Enclosed and gasketed</p>	18.0 (40.00)	1/2	50.8 (2.00)	0.99 (2.18)	GSK-50-20C
		3/4	50.8 (2.00)	0.89 (1.96)	GSK-75-20C
GS — Cast Covers — Furnished with gasket and screws. Enclosed and gasketed for raintight fit					
 <p>Hub Cover</p>	113.4 (250.00)	1/2	44.5 (1.75)	1.60 (1.60)	GSK-50-20
		3/4	44.5 (1.75)	1.60 (1.60)	GSK-75-20
				Weight in kg (lbs)	Catalog Number
GS — Gasket, Neoprene					
				0.27 (0.06)	GS-GK20-R