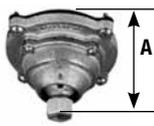
 


# GS Conduit Outlet Boxes, Covers and Hangers

UNILETS™ for use with Threaded Rigid Metal Conduit and IMC.

NEC:  
Rated for Ordinary Locations


COMMERCIAL AND INDUSTRIAL FITTINGS: CONDUIT OUTLET BODIES

Description	Hub Size (Inches)	Depth in Millimeters (Inches) (A)	Catalog Number
GS — Gasket, Neoprene 	—	—	GS-GK20-R
GS Flexible Fixture Hangers — Form 20 — Furnished with gasket and screws			
 <b>Ball Type</b> 15° swing in all directions, support 113.4 kg (250 lb)	—	76.2 (3.00)	<b>GSK-50-20B</b>
	—	82.6 (3.25)	<b>GSK-75-20B</b>
 <b>Cushion Type</b> Enclosed and gasketed — 8° swing in all directions. Cushions 18.1 kg (40 lb), supports 113.4 kg (250 lb)	—	50.8 (2.00)	<b>GSK-50-20C</b>
	—	50.8 (2.00)	<b>GSK-75-20C</b>


## Wiring Capacity

Hub Size (Inches)	Capacity dm <sup>3</sup> (in <sup>3</sup> )		
	GS	Hub	GSK Covers
			Blank
1/2	0.39 (24.00)	0.14 (8.50)	0.14 (8.50)
3/4	0.39 (24.00)	0.14 (8.50)	0.14 (8.50)
1	0.39 (24.00)	0.14 (8.50)	0.14 (8.50)

## Dimensions in Millimeters (Inches)

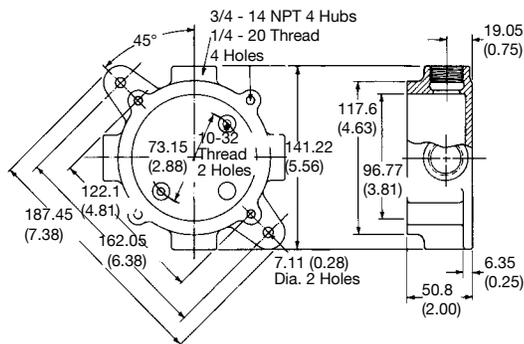

**GSU-20**  
Inside Depth 44.5 mm (1.75")

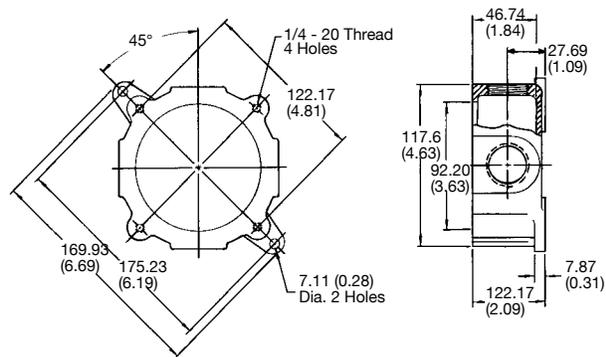

**GSU-100**  
Inside Depth 44.5 mm (1.75")