

GUBBM Instrument Enclosures

Explosionproof, Dust-Ignitionproof

GUBBM: Furnished with one 3/4" threaded conduit opening. Aluminum body with aluminum/glass cover.

NEC/CEC: ♦
 Class I, Division 1 and 2, Group D
 Class II, Division 1 and 2, Groups E, F, G
 Class III
 NEMA 3, 3R, 4

ENCLOSURES AND JUNCTION BOXES: NEC/CEC EXPLOSIONPROOF ENCLOSURES

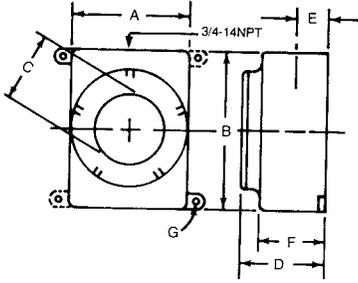
	Type Box	Conduit Opening Size (Inches-NPT)	Cover Opening mm (in)	Wall Thickness mm (in)	Form Number	Catalog Number
	GUBB-11A	3/4	136.7 (5.38)	11.2 (0.44)	1	GUBBM-1A
	GUBB-22A	3/4	182.6 (7.19)	11.2 (0.44)	2	GUBBM-2A
	GUBB-33A	3/4	246.1 (9.69)	14.2 (0.56)	3	GUBBM-3A

Other drilled and tapped conduit opening arrangements and sizes available in addition to the one 3/4" conduit opening provided.

GUBB Cast Junction Boxes for Drilling and Tapping Blank Body Ordering Information

For Covers and Mounting Plates, Order from GUBB Surface and Special Purpose Covers page.

APPLETON™

	Type Box	Mounting Lugs	Dimensions in Millimeters (Inches)						
			A	B	C	D	E	F	G
	GUBBM-1A	2	165.1 (6.50)	177.8 (7.00)	79.5 (3.13)	143.0 (5.63)	52.3 (2.06)	117.6 (4.63)	12.7 (0.50)
	GUBBM-2A	2	203.2 (8.00)	254.0 (10.00)	120.7 (4.75)	143.0 (5.63)	52.3 (2.06)	117.6 (4.63)	12.7 (0.50)
	GUBBM-3A	4	304.8 (12.00)	304.8 (12.00)	174.8 (6.88)	227.1 (8.94)	88.9 (3.50)	136.7 (5.38)	16.0 (0.63)

♦ Not UL Listed or CSA Certified.