

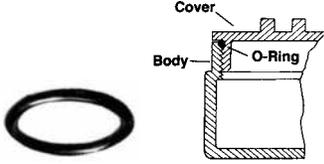
# GUBB/GUBBM Cast Junction Box Covers

## Explosionproof, Dust-Ignitionproof

Covers provide raintight fit when used with O-rings. Available in malleable iron, aluminum, and aluminum/glass.

**NEC/CEC:**

Class I, Division 1 and 2, Group D  
 Class II, Division 1 and 2, Groups E, F, G  
 Class III  
 NEMA 3, 3R, 4

		Fits Box Catalog Number	Nominal Cover Depth mm (in)	Nominal Cover Diameter mm (in)	Window Diameter mm (in)	Form Number	Catalog Number
<b>Covers — Aluminum — O-ring Gasket Included</b>							
 GUBK-1, GUBK-2	 GUBK-3	GUBB-11 (11A)	Surface	136.7 (5.38)	53.8 (2.12)	1	<b>GUBK-1</b>
		GUBB-22 (22A)	Surface	182.6 (7.19)	120.7 (4.75)	2	<b>GUBK-2</b>
		GUBB-33 (33A)	Surface	246.1 (9.69)	177.8 (7.00)	3	<b>GUBK-3</b>
<b>Instrument Box Covers — Aluminum and Glass</b>							
 GUBMK-1, GUBMK-2	 GUBMK-3	GUBB-11 (11A)	—	136.7 (5.38)		1	<b>GUBMK-1</b>
		GUBB-22 (22A)	—	182.6 (7.19)		2	<b>GUBMK-2</b>
		GUBB-33 (33A)	—	246.1 (9.69)		3	<b>GUBMK-3</b>
<b>Replacement O-rings — Neoprene</b>							
	Provide raintight fit for GUBB, GUBBM Boxes						
	GUBB-11 (11A)					1	<b>GUBG-1</b>
	GUBB-22 (22A)					2	<b>GUBG-2</b>
	GUBB-33 (33A)					3	<b>GUBG-3</b>
<b>Mounting Plates — 3.3 mm (0.13") Thick Aluminum. 4 standoffs, 4 mounting screws</b>							
	GUBB-11 (11A) ①			114.3 x 114.3 (4.50 x 4.50)		1	<b>GUBBMP-11</b>
	GUBB-22 (22A) ①			165.1 x 165.1 (6.50 x 6.50)		2	<b>GUBBMP-22</b>
	GUBB-33 (33A) ①			228.6 x 228.6 (9.00 x 9.00)		3	<b>GUBBMP-33</b>

① GUBB boxes are Pre-Drilled to accept a mounting plate.