

ATX™ HBDA Series Rectangular Bulkhead Luminaires

Flameproof. Compact Fluorescent, Incandescent


ATEX:
Zone 1 and 2 - 21 and 22
II 2 GD
IP66 - IK09

Appleton

INCANDESCENT/AREA: ATEX/IECEx FLAMEPROOF

Number of Lamps (not supplied)	Lamp Type and Wattage	Cable Entries	Weight kg (lb)	Volume dm ³ (in ³)	Catalog Number
1	18/20 W Compact Fluorescent	M20	5.7 (12.57)	9 (549.2)	HBDAF118
2	40 W Incandescent	M20	5.7 (12.57)	9 (549.2)	HBDAI240

Dimensions in Millimeters (Inches)

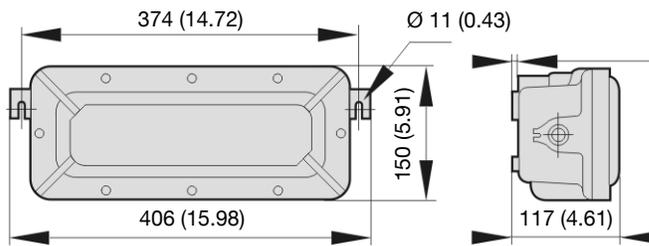

Photometric Data

Polar curves for a 1000 lm flux, according to NF C 71-120.
Luminaire symbol according to NF C 71-121.

--- Longitudinal
— Transverse

Degree	Candela Distribution	
	(0-180)	(90-270)
0	134	134
5	129	133
10	127	135
15	126	136
20	125	135
25	119	131
30	109	127
35	89	122
40	69	119
45	51	114
50	39	105
60	26	84
70	11	35

