


Industrial Areamaster™ LED Flood/High Bay Luminaires

For Ordinary Locations. 250 W, 400 W, 750 W HID Light Level Equivalent

NEC/CEC:
Type 3R, 4X
IP66, IP67
Suitable for use in Wet Locations
Marine Outside Type (Salt Water)

Order using catalog numbering guide below or select catalog number from tables on following pages.

Catalog Numbering Guide – Industrial Areamaster LED

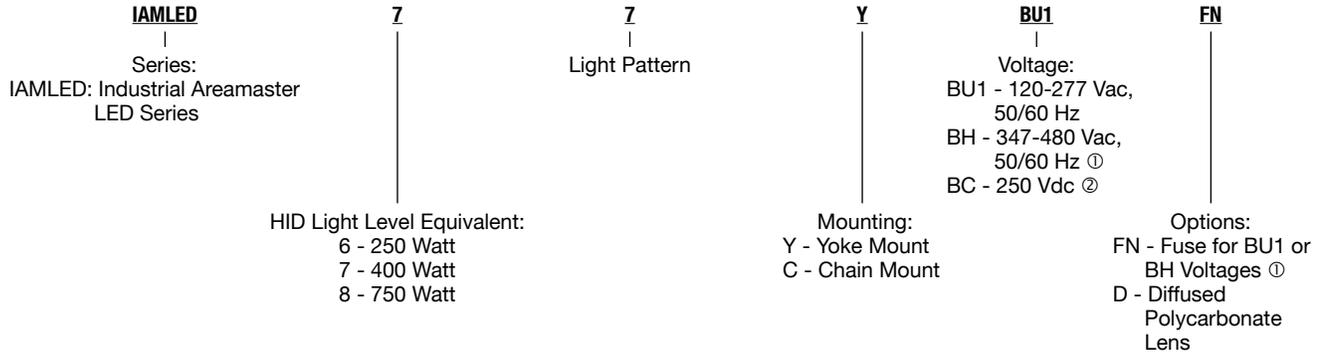

Electrical Specifications – Flood Mount

Catalog Number	Voltage Range	Frequency (Hz)	Watts Input Power (Nom.)	Input Amps (Max.)	Total Harmonic Distortion	Power Factor
IAMLED67YBU1	120-277 Vac	50/60	86/85	0.72 - 0.32	0.5	> 0.98
IAMLED67YBH	347-480 Vac	50/60	88/90	0.25 - 0.19	0.5	> 0.96
IAMLED77YBU1	120-277 Vac	50/60	125/121	1.10 - .047	0.5	> 0.98
IAMLED77YBH	347-480 Vac	50/60	124/125	0.35 - 0.25	0.5	> 0.96
IAMLED77YBC	250 Vdc	—	118	0.47	0.5	> 0.98
IAMLED87YBU1	120-277 Vac	50/60	176/175	1.60 - 0.70	0.5	> 0.98

Line Voltage	Catalog Number
120-277 Vac, 50/60 Hz	IAMLED67YBU1
120-277 Vac, 50/60 Hz	IAMLED77YBU1
120-277 Vac, 50/60 Hz	IAMLED87YBU1
347-480 Vac, 50/60 Hz	IAMLED67YBH
347-480 Vac, 50/60 Hz	IAMLED77YBH
250 Vdc	IAMLED77YBC



① Not available for use on the 750 Watt equivalent.
② Not available for use on the 250 and 750 Watt equivalent.