

PAPL Portable Two and Four Lamp Factory Sealed Fluorescent Luminaire



Explosionproof, Dust-Ignitionproof

120 V. Suitable for Wet Locations and Paint Spray Booths. UL Listed for Horizontal use only.

NEC/CEC:
Class I, Division 1 and 2, Groups C, D

	Lamps Included	Volts	Temperature Rating	Catalog Number
 <p>Two-Lamp Luminaire Illustrated</p>	Two-Lamp Luminaires Less Reflector			
	(2) 40 W F40BX	120	T6	PAPL240-120
	Reflector Only			
	Aluminum reflector with white powder coat polyester finish			
				APL2R
	Four-Lamp Luminaires Less Reflector			
	(4) 40 W F40BX	120	T6	PAPL440-120
	Reflector Only			
	Aluminum reflector with white powder coat polyester finish			
				APL4R

Dimensions in Millimeters (Inches)

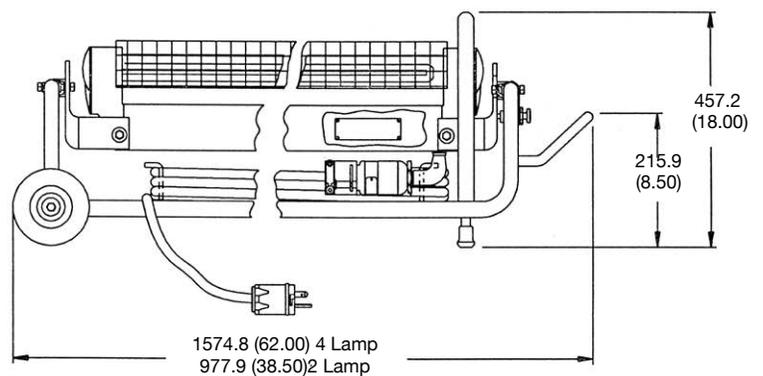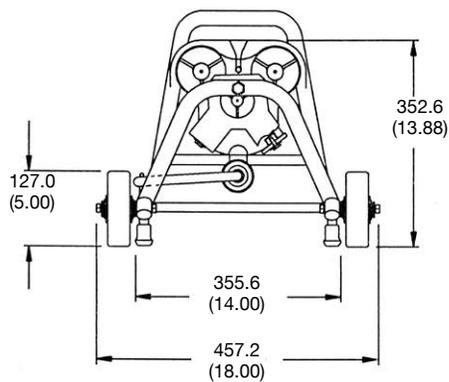

Appleton®

FLUORESCENT/AREA: NEC/CEC EXPLOSIONPROOF