


Cable Gland Accessories and Tools

For Cable Entries

	Thread	Dimensions (mm)		Weight (lbs/kg)	Catalog Number
		B	C		
316L Stainless Steel Serrated Washers					
	M16	0.75/19.0	1.00/25.4	0.02/0.01	16SW4
	M20	0.94/24.0	1.26/32.0	0.02/0.01	20SW4
	M25	1.30/33.0	1.57/40.0	0.02/0.01	25SW4
	M32	1.65/42.0	1.73/44.0	0.02/0.01	32SW4
	M40	2.17/55.0	2.32/59.0	0.04/0.02	40SW4
	M50	2.56/65.0	3.15/80.0	0.04/0.02	50SW4
	M63	2.76/70.0	3.94/100.0	0.13/0.06	63SW4
	M75	3.35/85.0	4.41/112.0	0.20/0.09	75SW4
	M90	3.94/100.0	4.72/120.0	0.24/0.11	90SW4
	M100	4.33/110.0	5.91/150.0	0.35/0.16	100SW4

Cable Gland Size	Catalog Number
Lead Star Clamp for E2FX and E2FW Cable Glands Lead Sheath Continuity	
2016	2016LSW
20S	20SLSW
20	20LSW
25S & 25	25LSW
32	32LSW
40	40LSW
50S	50SLSW
50	50LSW
63S	63SLSW
63	63LSW
75S	75SLSW
75	75LSW
90	90LSW
100	100LSW

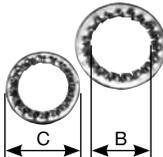

Cable Gland Size	E1FW – E2FW	A2F	PX	PX2K
	E1FX – E2FX T3			
Black PVC Shrouds				
20/16	PVC02	PVC02	PVC02	PVC06
20S	PVC04	PVC04	PVC04	PVC06
20	PVC06	PVC05	PVC05	PVC06
25S	PVC09	N.A.	N.A.	N.A.
25	PVC09	PVC09	PVC09	PVC09
32	PVC11	PVC10	PVC10	PVC11
40	PVC15	PVC13	PVC13	PVC15
50S	PVC18	PVC14	PVC15	PVC18
50	PVC21	PVC17	PVC18	PVC21
63S	PVC23	PVC20	PVC21	PVC23
63	PVC25	PVC22	PVC23	PVC25
75S	PVC28	PVC24	PVC24	PVC28
75	PVC30	PVC26	PVC26	PVC30
90	PVC32	PVC31	PVC31	PVC32
100	150-50HST	150-50HST	N.A.	N.A.

