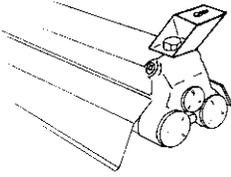
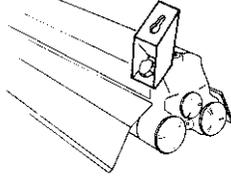


Fixture Hanger Bracket and Accessories

UNILETS® for use with Threaded Metal Conduit.

NEC/CEC:
Rated for Ordinary (Unclassified) Locations

POLES/HANGERS: NEC/CEC EXPLOSIONPROOF FLEXIBLE FIXTURE HANGERS

	NPT Size (Inches)	Support Weight kg (lbs)	Catalog Number
Fixture Hanger Brackets			
	3/4	90.0 (200)	FHS1
 <p>Ceiling Mount Projects light downward (90°). Shown mounted to Appleton AH260-118 explosionproof fluorescent lighting fixture.</p>			
 <p>Wall Mount Projects light at 45° angle. Shown mounted to Appleton AH260-118 explosionproof fluorescent lighting fixture.</p>			
Safety Support Hooks and Rigid Support for Dummy Side of Lighting Fixtures			
 <p>Installation View</p>	3/4	90.0 (200)	AC-KT
Complete assembly includes two hooks and one rigid support. Each hook supplied with a screw for closing 3/8" jaw opening. Rigid Support straddles max. 1-1/4" conduit. (Chain shown in installation view not furnished.)			
LC Steel Locking Couplings			
 <p>Installation View</p>	3/4	—	SLC75
	1	—	SLC1075
Setscrews with Allen head fasten on outside of hub and fixture stem. Prevents fixture stem from turning in hubs not normally supplied with setscrews. 3/4" fixture stem.			
Safety Support Hooks for Dummy Side of Lighting Fixtures			
Supplied with screw for closing 3/8" jaw opening.			
Male			
 <p>EFHM EFHF</p>	1/2	90.0 (200)	EFHM-50
	3/4		EFHM-75
Female			
	1/2	90.0 (200)	EFHF-50
	3/4		EFHF-75
Rigid Support for Fluorescent Lighting Fixtures (Dummy Side)			
	1/2 and 3/4	157.5 (350)	FHS5075
Will straddle max. 1-1/4" conduit.			