

U-Line™ 20 Amp Portable Receptacle with GFCI

Explosionproof, Dust-Ignitionproof

125 Vac. For use on Hazardous or Non-Hazardous Receptacles.

NEC/CEC:

Class I, Division 1 and 2 Groups C, D
 Class II, Division 1 and 2 Groups F, G
 Class III
 NEMA 3, 3R, 7CD, 9FG

Applications

- Provides required portable ground fault protection for electrically-operated devices. Meets all UL and CSA requirements for ground fault protection in hazardous locations.
- Well suited for use in highly corrosive atmospheres and wet locations.

Features

- Arcing is confined within the device's interior.
- Rated 20 Amp, 125 Vac, 5 mA trip setting.
- Provides open neutral protection to maximize safety.
- High intensity LED pilot light rated at 100,000 hours
- Smooth operating test and reset buttons.
- Heavy duty 0.91 meter (3 foot) SO power cord with U-Line™ 20 Amp NEMA 5-20R plug.
- Lightweight design.
- Convenient carry/hanging handle.
- Plug mates with competitors comparable receptacles. The receptacle also accepts their respective plugs.

Standard Materials

- Covers and back box: cast copperfree (less than 4/10ths of 1%) aluminum
- Cover bolts, test and reset buttons and shafts: stainless steel
- Carry/hanging handle: nylon covered galvanized steel

Standard Finish

- Covers and back box: baked gray epoxy clad finish


Options

- Incandescent pilot light available, contact local sales representative.

NEC/CEC Compliances and Certifications

- UL Standard: 943, 1203
- CSA Standard: C22.2 No. 30

Dimensions in Millimeters (Inches)

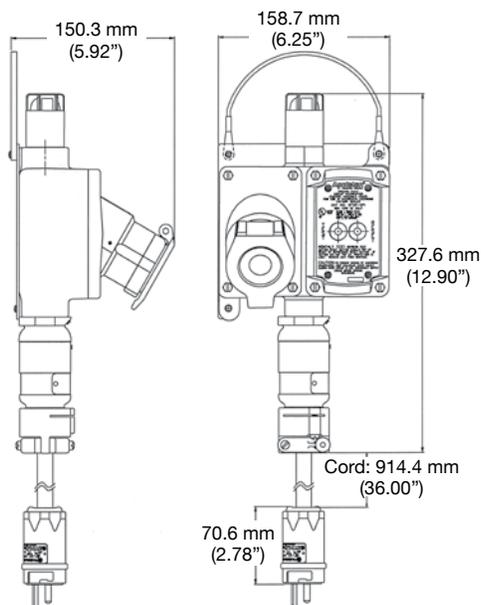

Amp	Pilot Light	Class I, Division 1 and 2
20	Green LED	U2023PGFID1G3
	Red LED	U2023PGFID1R3

PLUGS AND RECEPTACLES: NEC/CEC HAZARDOUS LOCATION

Appleton