


UniCode® Series Factory Sealed Control Station Configuration

Class I, Division 2, Groups B, C, D
 Class II, Groups E, F, G
 Class III
 Class I, Zone 2, Group IIC
 Type 3, 3R, 4, 4X
 IP66

Controls

Catalog Numbering Guide

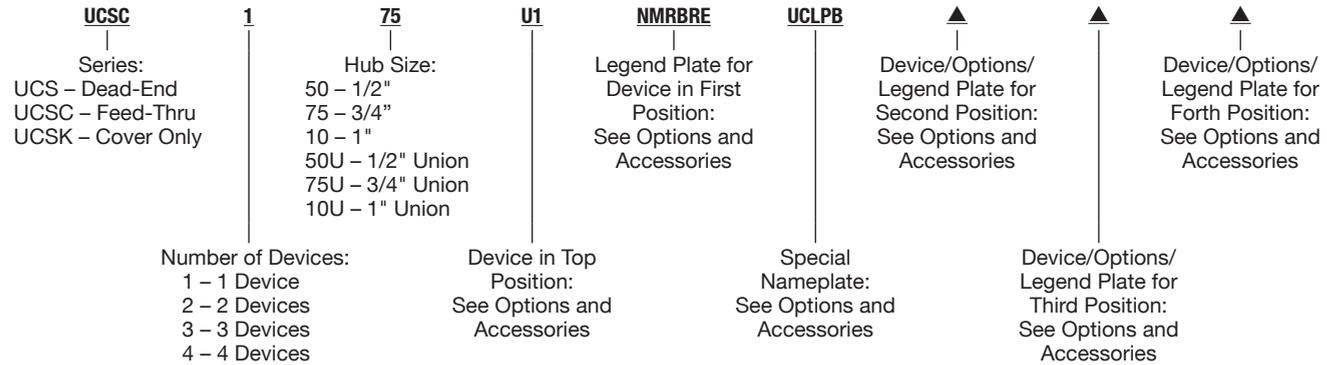

CONTROLS: HAZARDOUS LOCATION CONTROL STATIONS AND SWITCHES

Device Descriptions	Device Code
Momentary Push Button - 1NO/NC	U1 †
Momentary Push Button - 2NO/NC	UD1
Maintained Push Button - 1NO/NC	UM1
Maintained Push Button - 2NO/NC	UDM1
Pilot Light	J1 ‡
2-POS 2-CKT Selector Switch	12
3-POS 2-CKT Selector Switch	102
2-POS 4-CKT Selector Switch	35
3-POS 4-CKT Selector Switch (Labyrinth Switch Only)	345
Close-up Plug	PLG
Options Descriptions	Device Code
Amber Pilot Light	JGBA
Green Pilot Light	JGBG
Blue Pilot Light	JGBB
DC Rating for Pilot Light	DC
Red Mushroom Head - Momentary Push Button	NMRBRE
Green Mushroom Head - Momentary Push Button	NMRBGR
Black Mushroom Head - Momentary Push Button	NMRBBL
Black Mushroom Head - Maintained Push Button	NMRBMBL
Green Mushroom Head - Maintained Push Button	NMRBMGR
Spring Return from Right - Selector Switch (3 Position Only)	SRC
Spring Return from Left - Selector Switch (3 Position Only)	SLC
Spring Return from Right and Left - Selector Switch (3 Pos, 4 Ckt and Alt Contacts Only)	SRL
Alternate Contacts - Selector Switch	ALT
Red Momentary Push Button	PBRE
Green Momentary Push Button	PBGR
Accessories Descriptions	Accessory Code
Stainless Steel Mounting Feet	SSMTG
Mushroom Head Push Button Locking Guard	UCMPBLG

† Momentary push buttons are black. Add –PBRE for red or –PBGR for green.
 ‡ Pilot lights are red. Add –JGBA for amber, –JGBG for green or –JGBB for blue.