

Mounting Hoods, Globes, Guards and Reflectors for V and VH Incandescent Lighting Fixtures


60 thru 300W Incandescent Lamps.
For use with Threaded Rigid Metal Conduit and IMC.

	Size (Inches)	Catalogue Number	
		60-150W A-21	150-300W PS-25
	Pendant		
	1/2" 3/4"	VA140 VA240	VHA1400 VHA2400
	Ceiling - with Junction Box		
	Four Entry "X" 1/2" 3/4"	VGPX140 VGPX240	VHGPX1400 VHGPX2400
	Wall - Junction Box		
	Four Entry "X" 1/2" 3/4"	VGSX140 VGSX240	VHGSX1400 VHGSX2400
	Globes - Glass		
	Clear	VGL1CL	VH-700HR
	Clear - Heat Resistant	VGL1HR	
	Amber	VGL1AM	
	Blue	VGL1BL	
	Green	VGL1GR	
Red	VGL1RE		
	Globes - Polycarbonate*		
	Clear Max. 150W		
	Coloured Max. 100W		
	Mount Vertically		
	Clear	VPG1CL	
	Amber	VPG1AM	
Blue	VPG1BL		
Green	VPG1GR		
Red	VPG1RE		
	Guards - For Glass Globes		
	Cast Aluminum	V-680	VH-720

Parts and Dimensions – V and VH Incandescent Lighting Fixtures

		Description	Catalogue Number
V752		Replacement Parts Lamp Receptacle Porcelain - with mounting plate Fits all V and VH Series Fixtures	V-752
V930		Adapter Allows 150W V Series fixtures to accept 300W VH Series globes and guards	V-930
V2033		Globe Gasket 150W V Series 300W VH Series	V-2102 V-2033
V2030		Junction Box Gasket 150W V Series 300W VH Series	V-2030 V-F2032

Dimensions

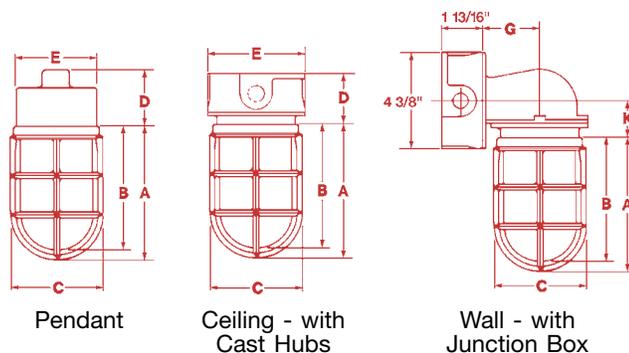

Size (Watts)	Pendant					Ceiling - with Junction Box				
	A	B	C	D	E	A	B	C	D	E

Dimensions in Inches

60-150	6.25	5.75	4.31	2.63	3.75	6.25	5.75	4.31	2.50	4.38
150-300	8.88	8.00	5.56	2.63	4.75	8.88	8.00	5.56	2.88	6.38

Dimensions in Centimetres

60-150	15.9	14.6	10.9	6.7	9.5	15.9	14.6	10.9	6.4	11.1
150-300	22.6	20.3	14.1	6.7	12.1	22.6	20.3	14.1	7.3	16.2

Size (Watts)	Wall - with Junction Box				
	A	B	C	G	K

Dimensions in Inches

60-150	6.25	5.75	4.31	2.63	1.75
150-300	8.88	8.00	5.56	3.69	1.75

Dimensions in Centimetres

60-150	15.9	14.6	10.9	6.4	4.5
150-300	22.6	20.3	14.1	7.3	4.5