

# F1-106


UL 1598A

## Stylmaster™ HID

### Enclosed and Gasketed Fixtures for Use with HID Remote Ballasts

Copper-Free Aluminum Mounting Hoods. Porcelain Steel and Polyester Reflectors.

See Page F2-10 for dimensions.

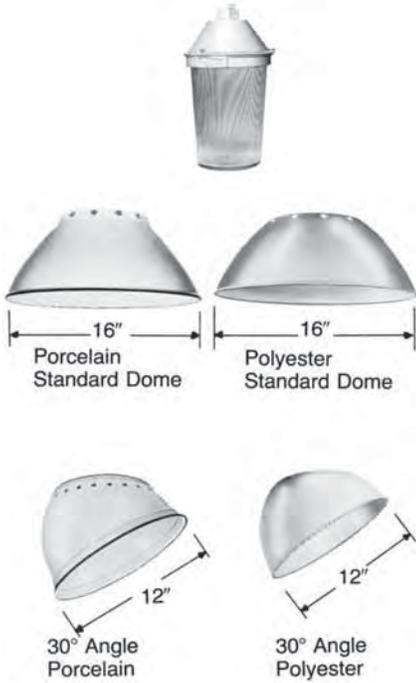

Description	Hub Size (Inches)	Catalog Number		
		With Globe	Globe and Guard	Hood Only
<b>Pendant</b>				
Rigid or Flexible Mounting				
Mogul Base — for 50 W-150 W HPS, and 175 W-250 W MH	1/2† 3/4	<b>VPAM2575</b>	<b>VPAM2575G</b>	<b>VPAM75</b>
<b>Porcelain Steel and Polyester Reflectors</b>				
For 50 W-150 W HPS, and 175 W-250 W MH		<b>Porcelain</b>	<b>Polyester</b>	
Standard Dome		<b>LPR-25ST</b>	<b>LPRP-25ST</b>	
30° Angle		<b>LPR-25AN</b>	<b>LPRP-25AN</b>	

† 3/4" Tapped opening – furnished with 3/4" to 1/2" reducer for 1/2" stems.