

# IDSR Interlocked Switched Receptacles

## Weatherproof. Watertight.


With Breaker or Disconnect Switch, Fusible or Non-fusible. For use with Powertite™ ACP plugs.

### CEC:

Listed for Ordinary (Unclassified) Locations  
NEMA 3, 5 or 3, 4X, 5

	Amp.	Fusing •	HP at 600 Vac 3-Phase ①	Without Viewing Window	With Viewing Window	Aux. Contacts ② 1 or 2 NO/NC		Mating Plug
	30	Fused	7.5/20	IDSR3034	IDSR3034-W	WS30AUX1	WS30AUX2	ACP3034BC
	60	Fused	15/50	IDSR6034	IDSR6034-W	WS60AUX1	WS60AUX2	ACP6034BC
	100	Fused	30/70	IDSR1034	IDSR1034-W	WS100AUX1	WS100AUX2	ACP1034CD
	30	Non-Fused	25	IDSR3034-NF	IDSR3034-NF-W	WS30AUX1	WS30AUX2	ACP3034BC
	60	Non-Fused	60	IDSR6034-NF	IDSR6034-NF-W	WS60AUX1	WS60AUX2	ACP6034BC
	100	Non-Fused	75	IDSR1034-NF	IDSR1034-NF-W	WS100AUX1	WS100AUX2	ACP1034CD

### Dimensions in Millimeters (Inches)

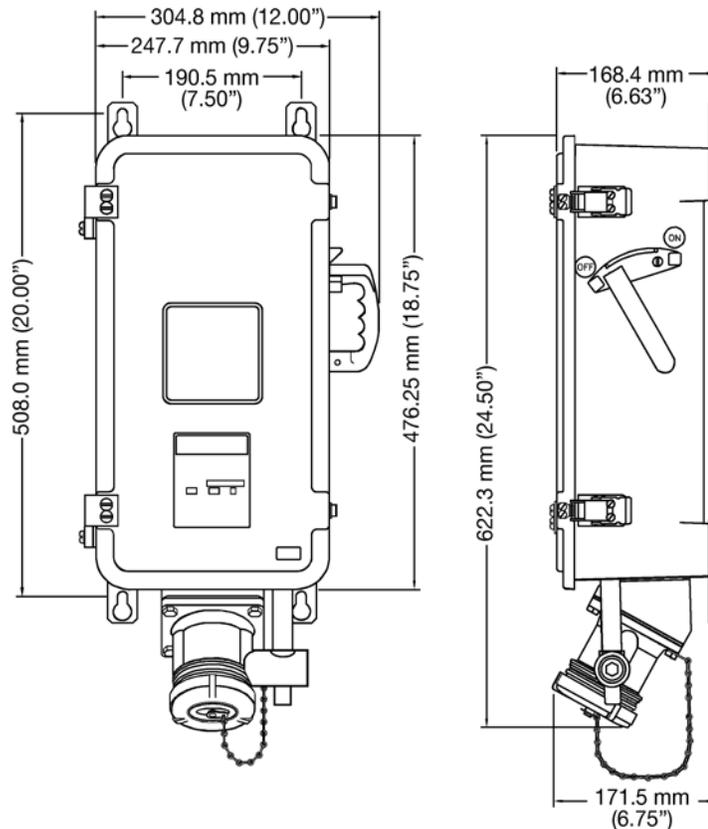

• Fuses not included.

① STD/MAX ratings based on type of fuse used eg. For IDSR 3034 – rated at 7.5 HP with standard fuse or rated at 20 HP with time delay fuse.

② Auxiliary contacts ordered separately for field installation.